

Quick Star Push-in Fittings – Inch Series



QSM Mini Series:
Thread Sizes: 10-32 UNF and
from 1/16 NPT to 1/4 NPT

QS Standard Series:
Thread Sizes: 10-32 UNF and
from 1/16 NPT to 1/2 NPT

QS Rotary with Ball Bearings:
Thread Sizes: 5/32 NPT
to 1/2 NPT

For complete dimensional
and technical information,
visit: www.festo.com/us
and view our online catalog,
or contact your Product
Support team via:
Phone: 1.800.99.FESTO
(1.800.993.3786)
Email: product.support@us.festo.com

Quick Star Push-in Fittings – Inch Series

1

1.1

Push-in Straight Fitting, UNF



Ordering Data				
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Wrench Size [inch]
153901*	QSM-10-32-UNF-1/8-U	10-32	1/8	5/16
164852*	QSM-10-32-UNF-5/32-U	10-32	5/32	5/16
164851	QS-10-32-UNF-3/16-U	10-32	3/16	1/2
164850	QS-10-32-UNF-1/4-U	10-32	1/4	1/2

Push-in Straight Fitting, NPT



Ordering Data				
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Wrench Size [inch]
153902*	QSM-1/16-1/8-U	1/16	1/8	5/16
190676*	QSM-1/6-5/32-U	1/16	5/32	7/16
153930*	QSM-1/8-1/8-U	1/8	1/8	7/16
190677*	QSM-1/8-5/32-U	1/8	5/32	7/16
190680*	QSM-1/4-1/8-U	1/4	1/8	9/16
192802*	QS-1/16-5/32-U	1/16	5/32	7/16
192803*	QS-1/16-3/16-U	1/16	3/16	1/2
190678*	QS-1/16-1/4-U	1/16	1/4	1/2
153601*	QS-1/8-5/32-U	1/8	5/32	7/16
153603*	QS-1/8-3/16-U	1/8	3/16	1/2
153605*	QS-1/8-1/4-U	1/8	1/4	1/2
153608*	QS-1/8-5/16-U	1/8	5/16	9/16
190679*	QS-1/8-3/8-U	1/8	3/8	11/16
153602*	QS-1/4-5/32-U	1/4	5/32	9/16
153604*	QS-1/4-3/16-U	1/4	3/16	9/16
153606*	QS-1/4-1/4-U	1/4	1/4	9/16
153609*	QS-1/4-5/16-U	1/4	5/16	9/16
153611*	QS-1/4-3/8-U	1/4	3/8	11/16
190681*	QS-1/4-1/2-U	1/4	1/2	7/8
153607*	QS-3/8-1/4-U	3/8	1/4	11/16
153610*	QS-3/8-5/16-U	3/8	5/16	11/16
153612*	QS-3/8-3/8-U	3/8	3/8	11/16
153614	QS-3/8-1/2-U	3/8	1/2	7/8
153613*	QS-1/2-3/8-U	1/2	3/8	7/8
153615	QS-1/2-1/2-U	1/2	1/2	7/8
190682*	QS-1/2-5/8-U	1/2	5/8	1

* Packaged in quantities of 10. (No asterisk = items sold by the unit.)
Ask Festo or your authorized Festo distributor about part numbers of items offered in bulk package sizes.

Quick Star Push-in Fittings – Inch Series

Push-in Straight Fitting, UNF, with Female Thread



Ordering Data				
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Wrench Size [inch]
153904*	QSMF-10-32-UNF-1/8-U	10-32	1/8	5/16
190699*	QSMF-10-32-UNF-5/32-U	10-32	5/32	5/16
190700*	QSF-10-32-UNF-3/16-U	10-32	3/16	1/2
190701*	QSF-10-32-UNF-1/4-U	10-32	1/4	1/2

Push-in Straight Fitting, NPT, with Female Thread



Ordering Data				
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Wrench Size [inch]
153616*	QSF-1/8-5/32-U	1/8	5/32	9/16
153618*	QSF-1/8-3/16-U	1/8	3/16	9/16
153620*	QSF-1/8-1/4-U	1/8	1/4	9/16
153622*	QSF-1/8-5/16-U	1/8	5/16	9/16
190702*	QSF-1/8-3/8-U	1/8	3/8	11/16
153617*	QSF-1/4-5/32-U	1/4	5/32	11/16
153619*	QSF-1/4-3/16-U	1/4	3/16	11/16
153621*	QSF-1/4-1/4-U	1/4	1/4	11/16
153623*	QSF-1/4-5/16-U	1/4	5/16	11/16
153625*	QSF-1/4-3/8-U	1/4	3/8	11/16
153624*	QSF-3/8-5/16-U	3/8	5/16	7/8
153626*	QSF-3/8-3/8-U	3/8	3/8	7/8
153627	QSF-3/8-1/2-U	3/8	1/2	7/8

Push-in Straight Fitting, UNF, with Internal Hex



Ordering Data				
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Wrench Size [inch]
190683*	QSM-10-32-UNF-1/8-I-U	10-32	1/8	5/64
190684*	QSM-10-32-UNF-5/32-I-U	10-32	5/32	3/32
190686*	QSM-10-32-UNF-3/16-I-U	10-32	3/16	3/32
190687*	QS-10-32-UNF-1/4-I-U	10-32	1/4	3/32

* Packaged in quantities of 10. (No asterisk = items sold by the unit.)
Ask Festo or your authorized Festo distributor about part numbers of items offered in bulk package sizes.

1
1.1

Quick Star Push-in Fittings – Inch Series

1

1.1

Push-in Straight Fitting, NPT, with Internal Hex



Ordering Data				
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Wrench Size [inch]
190685*	QSM-1/8-5/32-I-U	1/8	5/32	3/32
190689*	QSM-1/8-3/16-I-U	1/8	3/16	1/8
190688*	QS-1/8-5/32-I-U	1/8	5/32	3/32
190690*	QS-1/8-1/4-I-U	1/8	1/4	5/32
190691*	QS-1/8-5/16-I-U	1/8	5/16	3/16
190692*	QS-1/4-1/4-I-U	1/4	1/4	5/32
190693*	QS-1/4-5/16-I-U	1/4	5/16	7/32
190694*	QS-1/4-3/8-U	1/4	3/8	7/32
190695*	QS-3/8-5/16-I-U	3/8	5/16	7/32
190696*	QS-3/8-3/8-I-U	3/8	3/8	7/32
190697*	QS-3/8-1/2-I-U	3/8	1/2	5/16
190698*	QS-1/2-1/2-I-U	1/2	1/2	5/16

Push-in Straight Fitting, UNF, with Internal Shut-off



Ordering Data				
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Wrench Size [inch]
190703	QSMK-10-32-UNF-1/8-U	10-32	1/8	3/8
190704	QSMK-10-32-UNF-5/32-U	10-32	5/32	3/8
190706	QSMK-10-32-UNF-3/16-U	10-32	3/16	7/16
190707	QSK-10-32-UNF-1/4-U	10-32	1/4	1/2

Push-in Straight Fitting, NPT, with Internal Shut-off



Ordering Data				
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Wrench Size [inch]
192804	QSMK-1/16-1/8-U	1/16	1/8	3/8
192805	QSMK-1/16-5/32-U	1/16	5/32	3/8
192806	QSMK-1/16-3/16-U	1/16	3/16	7/16
192705	QSMK-1/8-5/32-U	1/8	5/32	7/16
190709	QSMK-1/8-3/16-U	1/8	3/16	7/16
192807	QSK-1/16-1/4-U	1/16	1/4	1/2
190710	QSK-1/8-1/4-U	1/8	1/4	1/2
190711	QSK-1/8-5/16-U	1/8	5/16	9/16
190712	QSK-1/4-1/4-U	1/4	1/4	9/16
190713	QSK-1/4-5/16-U	1/4	5/16	9/16
190714	QSK-1/4-3/8-U	1/4	3/8	11/16
190715	QSK-3/8-5/16-U	3/8	5/16	11/16
190716	QSK-3/8-3/8-U	3/8	3/8	11/16
190717	QSK-3/8-1/2-U	3/8	1/2	7/8
190718	QSK-1/2-1/2-U	1/2	1/2	7/8

* Packaged in quantities of 10. (No asterisk = items sold by the unit.)
Ask Festo or your authorized Festo distributor about part numbers of items offered in bulk package sizes.

Quick Star Push-in Fittings – Inch Series

Push-in Elbow Fitting, UNF



Ordering Data				
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Wrench Size [inch]
153907*	QSML-10-32-UNF-1/8-U	10-32	1/8	5/16
164849*	QSML-10-32-UNF-5/32-U	10-32	5/32	5/16
164848*	QSL-10-32-UNF-3/16-U	10-32	3/16	1/2
164847*	QSL-10-32-UNF-1/4-U	10-32	1/4	1/2

Push-in Elbow Fitting, NPT



Ordering Data				
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Wrench Size [inch]
153908*	QSML-1/16-1/8-U	1/16	1/8	7/16
190721*	QSML-1/16-5/32-U	1/16	5/32	7/16
192811*	QSML-1/16-3/16-U	1/16	3/16	7/16
153909*	QSML-1/8-1/8-U	1/8	1/8	7/16
190723*	QSML-1/4-1/8-U	1/4	1/8	9/16
192812*	QSL-1/16-1/4-U	1/16	1/4	1/2
153639*	QSL-1/8-5/32-U	1/8	5/32	7/16
153641*	QSL-1/8-3/16-U	1/8	3/16	1/2
153643*	QSL-1/8-1/4-U	1/8	1/4	1/2
153646*	QSL-1/8-5/16-U	1/8	5/16	9/16
190722*	QSL-1/8-3/8-U	1/8	3/8	11/16
153640*	QSL-1/4-5/32-U	1/4	5/32	9/16
153642*	QSL-1/4-3/16-U	1/4	3/16	9/16
153644*	QSL-1/4-1/4-U	1/4	1/4	9/16
153647*	QSL-1/4-5/16-U	1/4	5/16	9/16
153649*	QSL-1/4-3/8-U	1/4	3/8	11/16
190724*	QSL-1/4-1/2-U	1/4	1/2	7/8
153645*	QSL-3/8-1/4-U	3/8	1/4	11/16
153648*	QSL-3/8-5/16-U	3/8	5/16	11/16
153650*	QSL-3/8-3/8-U	3/8	3/8	11/16
153652*	QSL-3/8-1/2-U	3/8	1/2	7/8
153651*	QSL-1/2-3/8-U	1/2	3/8	7/8
153653	QSL-1/2-1/2-U	1/2	1/2	7/8
190725*	QSL-1/2-5/8-U	1/2	5/8	1

Push-in Elbow Fitting, UNF, Long



Ordering Data				
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Wrench Size [inch]
153910*	QSMLL-10-32-UNF-1/8-U	10-32	1/8	5/16

* Packaged in quantities of 10. (No asterisk = items sold by the unit.)
Ask Festo or your authorized Festo distributor about part numbers of items offered in bulk package sizes.

Quick Star Push-in Fittings – Inch Series

1

1.1

Push-in Elbow Fitting, NPT, Long



Ordering Data				
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Wrench Size [inch]
153911*	QSMML-1/16-1/8-U	1/16	1/8	7/16
153912*	QSMML-1/8-1/8-U	1/8	1/8	7/16
190734*	QSMML-1/4-1/8-U	1/4	1/8	9/16
153668*	QSL-1/8-5/32-U	1/8	5/32	7/16
153669*	QSL-1/8-3/16-U	1/8	3/16	1/2
153671*	QSL-1/8-1/4-U	1/8	1/4	1/2
153674*	QSL-1/8-5/16-U	1/8	5/16	9/16
190735*	QSL-1/4-5/32-U	1/4	5/32	9/16
153670*	QSL-1/4-3/16-U	1/4	3/16	9/16
153672*	QSL-1/4-1/4-U	1/4	1/4	9/16
153675*	QSL-1/4-5/16-U	1/4	5/16	9/16
153677*	QSL-1/4-3/8-U	1/4	3/8	11/16
190736*	QSL-1/4-1/2-U	1/4	1/2	7/8
153673*	QSL-3/8-1/4-U	3/8	1/4	11/16
153676*	QSL-3/8-5/16-U	3/8	5/16	11/16
153678*	QSL-3/8-3/8-U	3/8	3/8	11/16
153680*	QSL-3/8-1/2-U	3/8	1/2	7/8
153679*	QSL-1/2-3/8-U	1/2	3/8	7/8
153681*	QSL-1/2-1/2-U	1/2	1/2	7/8

Push-in Elbow Fitting, NPT, with Female Thread



Ordering Data				
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Wrench Size [inch]
190726*	QSLF-1/8-5/32-U	1/8	5/32	9/16
190727*	QSLF-1/8-3/16-U	1/8	3/16	9/16
190728*	QSLF-1/8-1/4-U	1/8	1/4	9/16
190729*	QSLF-1/8-5/16-U	1/8	5/16	9/16
190730*	QSLF-1/4-1/4-U	1/4	1/4	11/16
190731*	QSLF-1/4-5/16-U	1/4	5/16	11/16
164846*	QSLF-1/4-3/8-U	1/4	3/8	3/4
190732*	QSLF-3/8-5/16-U	3/8	5/16	7/8
190733*	QSLF-3/8-3/8-U	3/8	3/8	7/8

Push-in Elbow Fitting, UNF, with Internal Shut-off



Ordering Data				
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Wrench Size [inch]
190737	QSMKL-10-32-UNF-1/8-U	10-32	1/8	1
190738	QSMKL-10-32-UNF-5/32-U	10-32	5/32	1
190739	QSMKL-10-32-UNF-3/16-U	10-32	3/16	1/2
190740	QSKL-10-32-UNF-1/4-U	10-32	1/4	1/2

* Packaged in quantities of 10. (No asterisk = items sold by the unit.)
Ask Festo or your authorized Festo distributor about part numbers of items offered in bulk package sizes.


Quick Star Push-in Fittings – Inch Series

Push-in Elbow Fitting, NPT, with Internal Shut-off



Ordering Data				
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Wrench Size [inch]
192813	QSMKL-1/16-1/8-U	1/16	1/8	7/16
192814	QSMKL-1/16-5/32-U	1/16	5/32	7/16
192815	QSMKL-1/16-3/16-U	1/16	3/16	1/2
190741	QSMKL-1/8-5/32-U	1/8	5/32	7/16
190742	QSMKL-1/8-3/16-U	1/8	3/16	1/2
192816	QSKL-1/16-1/4-U	1/16	1/4	1/2
190743	QSKL-1/8-1/4-U	1/8	1/4	1/2
190744	QSKL-1/8-5/16-U	1/8	5/16	9/16
190745	QSKL-1/4-1/4-U	1/4	1/4	9/16
190746	QSKL-1/4-5/16-U	1/4	5/16	9/16
190747	QSKL-1/4-3/8-U	1/4	3/8	11/16
190748	QSKL-3/8-5/16-U	3/8	5/16	11/16
190749	QSKL-3/8-3/8-U	3/8	3/8	11/16
190750	QSKL-3/8-1/2-U	3/8	1/2	7/8
190751	QSKL-1/2-1/2-U	1/2	1/2	7/8

Push-in Elbow Fitting, NPT, with External Hex

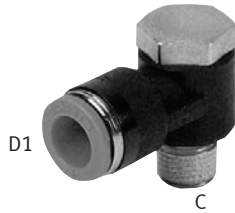

Ordering Data				
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Wrench Size [inch]
153682*	QSLV-1/8-5/32-U	1/8	5/32	9/16
153683*	QSLV-1/8-3/16-U	1/8	3/16	9/16
153685*	QSLV-1/8-1/4-U	1/8	1/4	9/16
153687*	QSLV-1/8-5/16-U	1/8	5/16	9/16
153684*	QSLV-1/4-3/16-U	1/4	3/16	11/16
153686*	QSLV-1/4-1/4-U	1/4	1/4	11/16
153688*	QSLV-1/4-5/16-U	1/4	5/16	11/16
153690*	QSLV-1/4-3/8-U	1/4	3/8	11/16
153689*	QSLV-3/8-5/16-U	3/8	5/16	7/8
153691*	QSLV-3/8-3/8-U	3/8	3/8	7/8
153692*	QSLV-3/8-1/2-U	3/8	1/2	7/8
153693	QSLV-1/2-1/2-U	1/2	1/2	1
190752	QSLV-1/2-5/8-U	1/2	5/8	1

* Packaged in quantities of 10. (No asterisk = items sold by the unit.)
Ask Festo or your authorized Festo distributor about part numbers of items offered in bulk package sizes.

1
1.1

Quick Star Push-in Fittings – Inch Series

1

1.1

Push-in Elbow Fitting, NPT, with Internal Hex



Ordering Data				
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Wrench Size [inch]
190753*	QSLV-1/8-5/32-I-U	1/8	5/32	5/32
190754*	QSLV-1/8-3/16-I-U	1/8	3/16	3/16
190755*	QSLV-1/8-1/4-I-U	1/8	1/4	3/16
190756*	QSLV-1/8-5/16-I-U	1/8	5/16	5/16
190757*	QSLV-1/4-1/4-I-U	1/4	1/4	5/16
190758*	QSLV-1/4-5/16-I-U	1/4	5/16	5/16
190759*	QSLV-1/4-3/8-I-U	1/4	3/8	5/16
190760*	QSLV-3/8-5/16-I-U	3/8	5/16	5/16
190761*	QSLV-3/8-3/8-I-U	3/8	3/8	5/16
190762*	QSLV-3/8-1/2-I-U	3/8	1/2	1/2
190763*	QSLV-1/2-1/2-I-U	1/2	1/2	1/2
190764*	QSLV-1/2-5/8-I-U	1/2	5/8	9/16

Push-in Double Elbow Fitting, NPT



Ordering Data				
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Wrench Size [inch]
190765	QSLV2-1/8-5/32-U	1/8	5/32	9/16
190766	QSLV2-1/8-3/16-U	1/8	3/16	9/16
190767	QSLV2-1/8-1/4-U	1/8	1/4	9/16
190768	QSLV2-1/8-5/16-U	1/8	5/16	11/16
190769	QSLV2-1/4-1/4-U	1/4	1/4	9/16
190770	QSLV2-1/4-5/16-U	1/4	5/16	11/16
190771	QSLV2-1/4-3/8-U	1/4	3/8	7/8
190772	QSLV2-3/8-5/16-U	3/8	5/16	11/16
190773	QSLV2-3/8-3/8-U	3/8	3/8	7/8
190774	QSLV2-3/8-1/2-U	3/8	1/2	1 1/8
190775	QSLV2-1/2-1/2-U	1/2	1/2	1 1/8
190776	QSLV2-1/2-5/8-U	1/2	5/8	1 1/8

* Packaged in quantities of 10. (No asterisk = items sold by the unit.)
 Ask Festo or your authorized Festo distributor about part numbers of items offered in bulk package sizes.

Quick Star Push-in Fittings – Inch Series

Push-in Triple Elbow Fitting, NPT



Ordering Data				
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Wrench Size [inch]
190777	QSLV3-1/8-5/32-U	1/8	5/32	9/16
190778	QSLV3-1/8-3/16-U	1/8	3/16	9/16
190779	QSLV3-1/8-1/4-U	1/8	1/4	9/16
190780	QSLV3-1/8-5/16-U	1/8	5/16	11/16
190781	QSLV3-1/4-1/4-U	1/4	1/4	9/16
190782	QSLV3-1/4-5/16-U	1/4	5/16	11/16
190783	QSLV3-1/4-3/8-U	1/4	3/8	7/8
190784	QSLV3-3/8-5/16-U	3/8	5/16	11/16
190785	QSLV3-3/8-3/8-U	3/8	3/8	7/8
190786	QSLV3-3/8-1/2-U	3/8	1/2	1 1/8
190787	QSLV3-1/2-1/2-U	1/2	1/2	1 1/8
190788	QSLV3-1/2-5/8-U	1/2	5/8	1 1/8

Push-in Y Fitting, NPT



Ordering Data				
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Wrench Size [inch]
190838*	QSMY-1/8-1/8-U	1/8	1/8	7/16
190839*	QSMY-1/4-1/8-U	1/4	1/8	9/16
153735*	QSY-1/8-5/32-U	1/8	5/32	7/16
153737*	QSY-1/8-3/16-U	1/8	3/16	1/2
153739*	QSY-1/8-1/4-U	1/8	1/4	1/2
153742*	QSY-1/8-5/16-U	1/8	5/16	9/16
153736*	QSY-1/4-5/32-U	1/4	5/32	9/16
153738*	QSY-1/4-3/16-U	1/4	3/16	9/16
153740*	QSY-1/4-1/4-U	1/4	1/4	9/16
153743*	QSY-1/4-5/16-U	1/4	5/16	9/16
153745*	QSY-1/4-3/8-U	1/4	3/8	11/16
153741*	QSY-3/8-1/4-U	3/8	1/4	11/16
153744*	QSY-3/8-5/16-U	3/8	5/16	11/16
153746*	QSY-3/8-3/8-U	3/8	3/8	11/16
153748*	QSY-3/8-1/2-U	3/8	1/2	7/8
153747*	QSY-1/2-3/8-U	1/2	3/8	7/8
153749	QSY-1/2-1/2-U	1/2	1/2	7/8

* Packaged in quantities of 10. (No asterisk = items sold by the unit.)
 Ask Festo or your authorized Festo distributor about part numbers of items offered in bulk package sizes.

1
1.1

Quick Star Push-in Fittings – Inch Series

1
1.1

Push-in Elbow Y Fitting, NPT



Ordering Data				
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Wrench Size [inch]
153779	QSYL-1/8-5/32-U	1/8	5/32	7/16
153781	QSYL-1/8-3/16-U	1/8	3/16	1/2
153783	QSYL-1/8-1/4-U	1/8	1/4	1/2
153786	QSYL-1/8-5/16-U	1/8	5/16	9/16
153780	QSYL-1/4-5/32-U	1/4	5/32	9/16
153782	QSYL-1/4-3/16-U	1/4	3/16	9/16
153784	QSYL-1/4-1/4-U	1/4	1/4	9/16
153787	QSYL-1/4-5/16-U	1/4	5/16	9/16
153789	QSYL-1/4-3/8-U	1/4	3/8	11/16
153785	QSYL-3/8-1/4-U	3/8	1/4	11/16
153788	QSYL-3/8-5/16-U	3/8	5/16	11/16
153790	QSYL-3/8-3/8-U	3/8	3/8	11/16
153792	QSYL-3/8-1/2-U	3/8	1/2	7/8
153791	QSYL-1/2-3/8-U	1/2	3/8	7/8
153793	QSYL-1/2-1/2-U	1/2	1/2	7/8

Push-in Elbow Y Fitting, NPT, with External Hex



Ordering Data				
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Wrench Size [inch]
153794	QSYLV-1/8-3/16-U	1/8	3/16	9/16
153795	QSYLV-1/8-1/4-U	1/8	1/4	9/16
153796	QSYLV-1/4-5/16-U	1/4	5/16	11/16
153797	QSYLV-3/8-3/8-U	3/8	3/8	7/8
153798	QSYLV-1/2-1/2-U	1/2	1/2	1

Push-in Elbow Y Fitting, NPT, with Male and Female Thread



Ordering Data				
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Wrench Size [inch]
190834*	QSYTF-1/8-1/4-U	1/8	1/4	9/16
190835*	QSYTF-1/4-5/16-U	1/4	5/16	11/16
190836*	QSYTF-3/8-3/8-U	3/8	3/8	7/8
190837*	QSYTF-1/2-1/2-U	1/2	1/2	1

* Packaged in quantities of 10. (No asterisk = items sold by the unit.)
Ask Festo or your authorized Festo distributor about part numbers of items offered in bulk package sizes.

Quick Star Push-in Fittings – Inch Series

Push-in Double Y Fitting, NPT



Ordering Data				
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Wrench Size [inch]
153810	QSQ-1/8-5/32-U	1/8	5/32	7/16
153812	QSQ-1/8-3/16-U	1/8	3/16	1/2
153813	QSQ-1/8-1/4-U	1/8	1/4	1/2
153811	QSQ-1/4-5/32-U	1/4	5/32	9/16

Push-in Elbow Double Y Fitting, NPT



Ordering Data				
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Wrench Size [inch]
190789	QSLV4-1/8-5/32-U	1/8	5/32	9/16
190790	QSLV4-1/8-3/16-U	1/8	3/16	9/16
190791	QSLV4-1/8-1/4-U	1/8	1/4	9/16
190792	QSLV4-1/8-5/16-U	1/8	5/16	11/16
190793	QSLV4-1/4-1/4-U	1/4	1/4	9/16
190794	QSLV4-1/4-5/16-U	1/4	5/16	11/16
190795	QSLV4-1/4-3/8-U	1/4	3/8	7/8
190796	QSLV4-3/8-5/16-U	3/8	5/16	11/16
190797	QSLV4-3/8-3/8-U	3/8	3/8	1 1/8
190798	QSLV4-3/8-1/2-U	3/8	1/2	1 1/8
190799	QSLV4-1/2-1/2-U	1/2	1/2	1 1/8
190800	QSLV4-1/2-5/8-U	1/2	5/8	1 1/8

Push-in Elbow Triple Y Fitting, NPT



Ordering Data				
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Wrench Size [inch]
190801	QSLV6-1/8-5/32-U	1/8	5/32	9/16
190802	QSLV6-1/8-3/16-U	1/8	3/16	9/16
190803	QSLV6-1/8-1/4-U	1/8	1/4	9/16
190804	QSLV6-1/8-5/16-U	1/8	5/16	11/16
190805	QSLV6-1/4-1/4-U	1/4	1/4	9/16
190806	QSLV6-1/4-5/16-U	1/4	5/16	11/16
190807	QSLV6-1/4-3/8-U	1/4	3/8	7/8
190808	QSLV6-3/8-5/16-U	3/8	5/16	11/16
190809	QSLV6-3/8-3/8-U	3/8	3/8	7/8
190810	QSLV6-3/8-1/2-U	3/8	1/2	1 1/8
190811	QSLV6-1/2-1/2-U	1/2	1/2	1 1/8
190812	QSLV6-1/2-5/8-U	1/2	5/8	1 1/8

* Packaged in quantities of 10. (No asterisk = items sold by the unit.)
Ask Festo or your authorized Festo distributor about part numbers of items offered in bulk package sizes.

Quick Star Push-in Fittings – Inch Series

1

1.1

Push-in T Fitting, UNF



Ordering Data				
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Wrench Size [inch]
153914*	QSMT-10-32-UNF-1/8-U	10-32	1/8	5/16
190813*	QSMT-10-32-UNF-5/32-U	10-32	5/32	5/16
190815*	QST-10-32-UNF-3/16-U	10-32	3/16	1/2
190816*	QST-10-32-UNF-1/4-U	10-32	1/4	1/2

Push-in T Fitting, NPT



Ordering Data				
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Wrench Size [inch]
153915*	QSMT-1/16-1/8-U	1/16	1/8	7/16
190814*	QSMT-1/16-5/32-U	1/16	5/32	7/16
153916*	QSMT-1/8-1/8-U	1/8	1/8	7/16
190817*	QSMT-1/4-1/8-U	1/4	1/8	9/16
153694*	QST-1/8-5/32-U	1/8	5/32	7/16
153696*	QST-1/8-3/16-U	1/8	3/16	1/2
153698*	QST-1/8-1/4-U	1/8	1/4	1/2
153701*	QST-1/8-5/16-U	1/8	5/16	9/16
153695*	QST-1/4-5/32-U	1/4	5/32	9/16
153697*	QST-1/4-3/16-U	1/4	3/16	9/16
153699*	QST-1/4-1/4-U	1/4	1/4	9/16
153702*	QST-1/4-5/16-U	1/4	5/16	9/16
153704*	QST-1/4-3/8-U	1/4	3/8	11/16
153700*	QST-3/8-1/4-U	3/8	1/4	11/16
153703*	QST-3/8-5/16-U	3/8	5/16	11/16
153705*	QST-3/8-3/8-U	3/8	3/8	11/16
153707*	QST-3/8-1/2-U	3/8	1/2	7/8
153706*	QST-1/2-3/8-U	1/2	3/8	7/8
153708	QST-1/2-1/2-U	1/2	1/2	7/8

Push-in Branch T Fitting, UNF



Ordering Data				
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Wrench Size [inch]
153917*	QSMTL-10-32-UNF-1/8-U	10-32	1/8	5/16
190818*	QSMTL-10-32-UNF-5/32-U	10-32	5/32	5/16
190820*	QSTL-10-32-UNF-3/16-U	10-32	3/16	1/2
190821*	QSTL-10-32-UNF-1/4-U	10-32	1/4	1/2

* Packaged in quantities of 10. (No asterisk = items sold by the unit.)
 Ask Festo or your authorized Festo distributor about part numbers of items offered in bulk package sizes.

Quick Star Push-in Fittings – Inch Series

Push-in Branch T Fitting, NPT



Ordering Data				
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Wrench Size [inch]
153918*	QSMTL-1/16-1/8-U	1/16	1/8	7/16
190819*	QSMTL-1/16-5/32-U	1/16	5/32	7/16
153919*	QSMTL-1/8-1/8-U	1/8	1/8	7/16
190822*	QSMTL-1/4-1/8-U	1/4	1/8	9/16
153709*	QSTL-1/8-5/32-U	1/8	5/32	7/16
153711*	QSTL-1/8-3/16-U	1/8	3/16	1/2
153713*	QSTL-1/8-1/4-U	1/8	1/4	1/2
153716*	QSTL-1/8-5/16-U	1/8	5/16	9/16
153710*	QSTL-1/4-5/32-U	1/4	5/32	9/16
153712*	QSTL-1/4-3/16-U	1/4	3/16	9/16
153714*	QSTL-1/4-1/4-U	1/4	1/4	9/16
153717*	QSTL-1/4-5/16-U	1/4	5/16	9/16
153719*	QSTL-1/4-3/8-U	1/4	3/8	11/16
153715	QSTL-3/8-1/4-U	3/8	1/4	11/16
153718	QSTL-3/8-5/16-U	3/8	5/16	11/16
153720*	QSTL-3/8-3/8-U	3/8	3/8	11/16
153722	QSTL-3/8-1/2-U	3/8	1/2	7/8
153721	QSTL-1/2-3/8-U	1/2	3/8	7/8
153723	QSTL-1/2-1/2-U	1/2	1/2	7/8

Push-in T Fitting, NPT, with Male and Female Thread



Ordering Data				
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Wrench Size [inch]
190823*	QSTF-1/8-5/32-U	1/8	5/32	9/16
190824*	QSTF-1/8-3/16-U	1/8	3/16	9/16
190825*	QSTF-1/8-1/4-U	1/8	1/4	9/16
190826*	QSTF-1/8-5/16-U	1/8	5/16	9/16
190827*	QSTF-1/4-1/4-U	1/4	1/4	11/16
190828*	QSTF-1/4-5/16-U	1/4	5/16	11/16
190829*	QSTF-1/4-3/8-U	1/4	3/8	11/16
190830*	QSTF-3/8-5/16-U	3/8	5/16	7/8
190831*	QSTF-3/8-3/8-U	3/8	1/8	7/8
190832*	QSTF-3/8-1/2-U	3/8	1/2	7/8
190833*	QSTF-1/2-1/2-U	3/8	1/2	1

* Packaged in quantities of 10. (No asterisk = items sold by the unit.)
Ask Festo or your authorized Festo distributor about part numbers of items offered in bulk package sizes.

1
1.1

Quick Star Push-in Fittings – Inch Series

1

1.1

Push-in Triple Branch Reducing T Fitting, NPT



Ordering Data					
Part No.	Type	Thread C	For Tubing O.D.		Wrench Size
			D1	D2	
			[inch]	[inch]	[inch]
153799	QST3-1/8-3/16-5/32-U	1/8	3/16	5/32	1/2
153800	QST3-1/4-5/16-5/32-U	1/4	5/16	5/32	9/16
153801	QST3-1/4-5/16-3/16-U	1/4	5/16	3/16	9/16
153802	QST3-1/4-5/16-1/4-U	1/4	5/16	1/4	9/16
153803	QST3-3/8-3/8-5/16-U	3/8	3/8	5/16	11/16

Push-in Bulkhead Fitting, with Female NPT Thread



Ordering Data					
Part No.	Type	Thread C1	Thread C2	For Tubing O.D.	Wrench Size
		[NPT]	[UNF]	D1	
				[inch]	[inch]
153767*	QSSF-1/8-5/32-U	1/8	1/2-20	5/32	9/16
153768*	QSSF-1/8-3/16-U	1/8	9/16-18	3/16	11/16
153770*	QSSF-1/8-1/4-U	1/8	9/16-18	1/4	11/16
153772*	QSSF-1/8-5/16-U	1/8	5/8-18	5/16	3/4
190719*	QSSF-1/8-3/8-U	1/8	7/8-14	3/8	1
190720*	QSSF-1/4-5/32-U	1/4	1/2-20	5/32	11/16
153769*	QSSF-1/4-3/16-U	1/4	9/16-18	3/16	11/16
153771*	QSSF-1/4-1/4-U	1/4	9/16-18	1/4	11/16
153773*	QSSF-1/4-5/16-U	1/4	5/8-18	5/16	3/4
153775*	QSSF-1/4-3/8-U	1/4	7/8-14	3/8	1
153774*	QSSF-3/8-5/16-U	3/8	5/8-18	5/16	3/4
153776*	QSSF-3/8-3/8-U	3/8	7/8-14	3/8	1
153777*	QSSF-3/8-1/2-U	3/8	7/8-14	1/2	1
153778*	QSSF-1/2-1/2-U	1/2	7/8-14	1/3	1

* Packaged in quantities of 10. (No asterisk = items sold by the unit.)
Ask Festo or your authorized Festo distributor about part numbers of items offered in bulk package sizes.

Quick Star Push-in Fittings – Inch Series – QS Rotary

Push-in Straight Fitting, NPT with Ball Bearing



Ordering Data					
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Max. RPM	Wrench Size [inch]
153951	QSR-1/8-5/32-U	1/8	5/32	500	1/2
153952	QSR-1/8-3/16-U	1/8	3/16	500	9/16
153954	QSR-1/8-1/4-U	1/8	1/4	500	9/16
153956	QSR-1/8-5/16-U	1/8	5/16	400	11/16
153953	QSR-1/4-3/16-U	1/4	3/16	500	9/16
153955	QSR-1/4-1/4-U	1/4	1/4	500	11/16
153957	QSR-1/4-5/16-U	1/4	5/16	400	11/16
153958	QSR-3/8-5/16-U	3/8	5/16	400	11/16
153959	QSR-3/8-3/8-U	3/8	3/8	300	7/8
153961	QSR-3/8-1/2-U	3/8	1/2	250	1
153960	QSR-1/2-3/8-U	1/2	3/8	300	7/8
153962	QSR-1/2-1/2-U	1/2	1/2	250	1

Push-in Elbow Fitting, NPT with Ball Bearing



Ordering Data					
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Max. RPM	Wrench Size [inch]
153963	QSRL-1/8-5/32-U	1/8	5/32	500	1/2
153964	QSRL-1/8-3/16-U	1/8	3/16	500	9/16
153966	QSRL-1/8-1/4-U	1/8	1/4	500	9/16
153968	QSRL-1/8-5/16-U	1/8	5/16	400	11/16
153965	QSRL-1/4-3/16-U	1/4	3/16	500	9/16
153967	QSRL-1/4-1/4-U	1/4	1/4	500	9/16
153969	QSRL-1/4-5/16-U	1/4	5/16	400	11/16
153970	QSRL-3/8-5/16-U	3/8	5/16	400	11/16
153971	QSRL-3/8-3/8-U	3/8	3/8	300	7/8
153973	QSRL-3/8-1/2-U	3/8	1/2	250	1
153972	QSRL-1/2-3/8-U	1/2	3/8	300	7/8
153974	QSRL-1/2-1/2-U	1/2	1/2	250	1

* Packaged in quantities of 10. (No asterisk = items sold by the unit.)
Ask Festo or your authorized Festo distributor about part numbers of items offered in bulk package sizes.

Festo - Your Partner in Automation



1 Festo Inc.
5300 Explorer Drive
Mississauga, ON L4W 5G4
Canada

Festo Customer Interaction Center
Tel: 1 877 463 3786
Fax: 1 877 393 3786
Email: customer.service.ca@festo.com

2 Festo Pneumatic
Av. Ceylán 3,
Col. Tequesquináhuac
54020 Tlalneantla,
Estado de México

Multinational Contact Center
01 800 337 8669
ventas.mexico@festo.com

3 Festo Corporation
1377 Motor Parkway
Suite 310
Islandia, NY 11749

Festo Customer Interaction Center
1 800 993 3786
1 800 963 3786
customer.service.us@festo.com

4 Regional Service Center
7777 Columbia Road
Mason, OH 45040

Connect with us



www.festo.com/socialmedia



www.festo.com

Subject to change