


# Electrical adapter NEFF with additional function

Technical data

**Plug socket NEFF-S1G44LB**

- Plug socket for operating an interlock-capable valve terminal interface in I-Port operation only

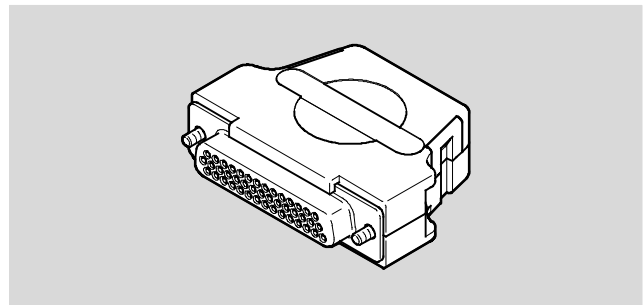

General technical data		
Max. tightening torque	[Nm]	0.24
Degree of protection EN 60529		IP40 (assembled)

Materials	
Note on materials	RoHS-compliant

Operating and environmental conditions		
Ambient temperature	[°C]	-5 ... +50

**Dimensions** Download CAD data → [www.festo.com](http://www.festo.com)

Type	B1	H1	H2	L1
NEFF-S1G44LB	16	42.5	38	53.7

Ordering data		
	Part No.	Type
Plug socket	1589339	NEFF-S1G44LB