


Electrical adapter NEFF with additional function

Technical data

Plug socket NEFF-S1G44LB

- Plug socket for operating an interlock-capable valve terminal interface in I-Port operation only

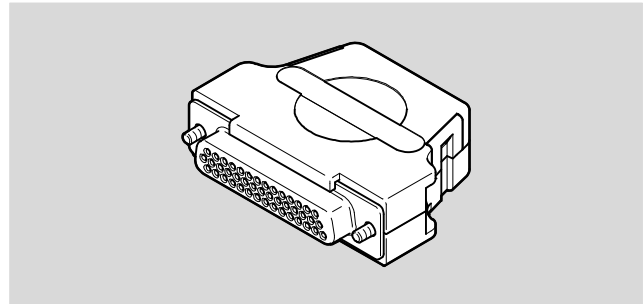

| General technical data | | |
|-------------------------------|------|------------------|
| Max. tightening torque | [Nm] | 0.24 |
| Degree of protection EN 60529 | | IP40 (assembled) |

| Materials | |
|-------------------|----------------|
| Note on materials | RoHS-compliant |

| Operating and environmental conditions | | |
|--|------|------------|
| Ambient temperature | [°C] | -5 ... +50 |

Dimensions Download CAD data → www.festo.com

| Type | B1 | H1 | H2 | L1 |
|--------------|----|------|----|------|
| NEFF-S1G44LB | 16 | 42.5 | 38 | 53.7 |

| Ordering data | | |
|---------------|----------|--------------|
| | Part No. | Type |
| Plug socket | 1589339 | NEFF-S1G44LB |

Festo - Your Partner in Automation



1 Festo Inc.
5300 Explorer Drive
Mississauga, ON L4W 5G4
Canada

Festo Customer Interaction Center
Tel: 1 877 463 3786
Fax: 1 877 393 3786
Email: customer.service.ca@festo.com

2 Festo Pneumatic
Av. Ceylán 3,
Col. Tequesquináhuac
54020 Tlalnepantla,
Estado de México

Multinational Contact Center
01 800 337 8669
ventas.mexico@festo.com

3 Festo Corporation
1377 Motor Parkway
Suite 310
Islandia, NY 11749

Festo Customer Interaction Center
1 800 993 3786
1 800 963 3786
customer.service.us@festo.com

4 Regional Service Center
7777 Columbia Road
Mason, OH 45040

Connect with us



www.festo.com/socialmedia



www.festo.com

Subject to change