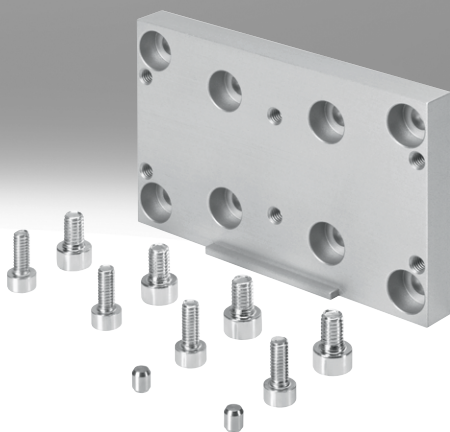


Adapter for drives

FESTO




Adapter for rotary modules ERMB

Accessories

Adapter kit
DHAA, HAPB

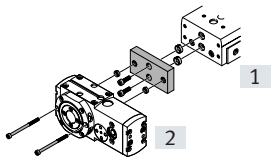
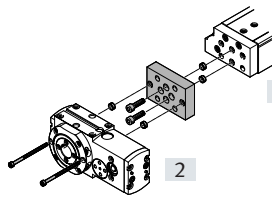
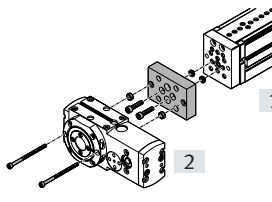
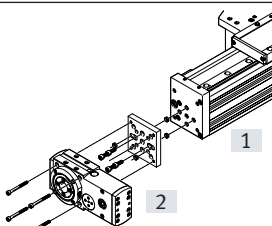
Material:
Wrought aluminium alloy
Free of copper and PTFE
RoHS-compliant

 **Note**

The kit includes the individual mounting interface as well as the necessary mounting material.

Permissible drive/drive combinations with adapter kit

Download CAD data → www.festo.com

Combination	[1] Drive Size	[2] Drive Size	Adapter kit			
			CRC ¹⁾	Part no.	Type	PU ²⁾
DGST/ERMB	DGST	ERMB	DHAA			
	20	20	2	8162108	DHAA-D-G8-20-R1-20	1
	25	25		8162109	DHAA-D-G8-25-R1-25	1
DGSL/ERMB	DGSL	ERMB	HAPB			
	16, 20, 25	20	2	558306	HAPB-38	1
	20, 25	25		558307	HAPB-39	1
	25	32		558308	HAPB-40	1
EGSL/ERMB	EGSL	ERMB	HAPB			
	45, 55, 75	20	2	558306	HAPB-38	1
	75	25		558307	HAPB-39	1
	75	32		558308	HAPB-40	1
ELCC/ERMB	ELCC	ERMB	HAPB			
	60, 70	20	2	558306	HAPB-38	1
	70, 90	25		558307	HAPB-39	1
	90, 110	32		558308	HAPB-40	1

 
1) More information www.festo.com/x/topic/crc

2) Packaging unit.

Accessories

Adapter kit EHAM

Material:
Wrought aluminium alloy
Free of copper and PTFE
RoHS-compliant

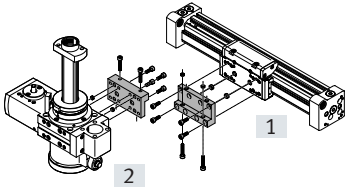
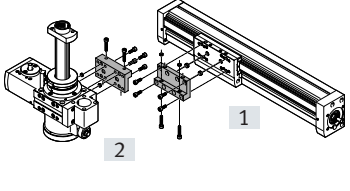


Note

The kit includes the individual mounting interface as well as the necessary mounting material.

Download CAD data → www.festo.com

Permissible drive/drive combinations with adapter kit

Combination	[1] Drive Size	[2] Drive Size	Adapter kit			PU ²⁾
			CRC ¹⁾	Part no.	Type	
DGC/EHMB	DGC	EHMB	EHAM			
	25	20	2	1132369	EHAM-H1-20-L2-80	1
	25	25		1132402	EHAM-H1-25-L2-80	1
	40	32		1132529	EHAM-H1-32-L2-120	1
EGC/EHMB	EGC	EHMB	EHAM			
	80	20	2	1132369	EHAM-H1-20-L2-80	1
	80	25		1132402	EHAM-H1-25-L2-80	1
	120	32		1132529	EHAM-H1-32-L2-120	1


1) More information www.festo.com/x/topic/crc

2) Packaging unit.

Accessories

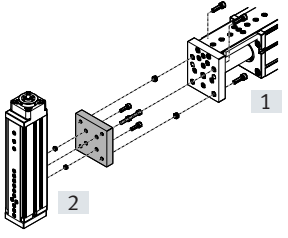
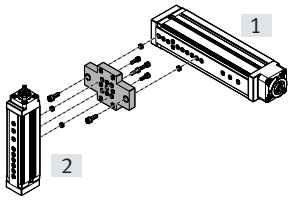
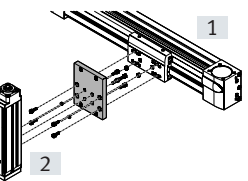
**Adapter kit
HMSV**

Material:
Wrought aluminium alloy
Free of copper and PTFE
RoHS-compliant

 **Note**
The kit includes the individual mounting interface as well as the necessary mounting material.

Permissible drive/drive combinations with adapter kit

Download CAD data → www.festo.com


Combination	[1] Drive Size	[2] Drive Size	Adapter kit			Quantity required	PU ²⁾
			CRC ¹⁾	Part no.	Type		
EGSL/EGSL	EGSL	EGSL	HMSV				
	35	35	2	–	M4x12 DIN 912 ³⁾	4	–
	45, 55	35		8146544	ZBH-7-B ⁴⁾	4	10
	45	45		1088295	HMSV-71	1	–
	55	45, 55		–	M5x12 DIN 912 ³⁾	4	–
	75	45, 55		8146544	ZBH-7-B ⁴⁾	4	10
	75	75		1088311	HMSV-72	1	–
	75	75		–	M6x18 DIN 912 ³⁾	4	–
	35	35	2	8137184	ZBH-9-B ⁴⁾	4	10
	45, 55	35, 45		1088327	HMSV-73	1	1
	75	45		1088338	HMSV-74	1	1
	55	55		1089092	HMSV-75	1	1
	75	55, 75		1088338	HMSV-74	1	1
	75	55, 75		1089092	HMSV-75	1	1
EGC/EGSL	EGC	EGSL	HMSV				
	50	35	2	1089104	HMSV-76	1	1
	70	35, 45, 55		1089346	HMSV-77	1	1
	80	45, 55, 75		1089520	HMSV-78	1	1
	120	45, 55, 75		1089527	HMSV-79	1	1

- 1) More information www.festo.com/x/topic/crc
- 2) Packaging unit.
- 3) The screws listed are not included in the scope of delivery of the drives.
- 4) The centring sleeves are included in the scope of delivery of the drives.

Accessories

Adapter kit DHAA

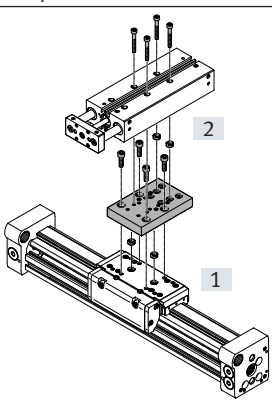
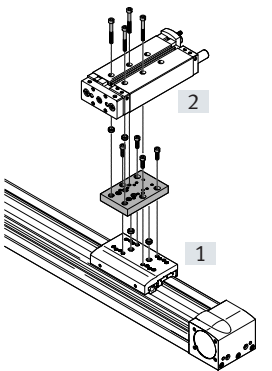
Material:
Wrought aluminium alloy
Free of copper and PTFE
RoHS-compliant

 **Note**

The kit includes the individual mounting interface as well as the necessary mounting material.

Download CAD data → www.festo.com

Permissible drive/drive combinations with adapter kit

Combination	[1] Drive Size	[2] Drive Size	Adapter kit			
			CRC ¹⁾	Part no.	Type	PU ²⁾
DGC/DFM	DGC	DFM	DHAA			
	25	12, 16, 20	2	562152	DHAA-D-L-25-G7-12	1
	32	20, 25		562153	DHAA-D-L-32-G7-20	1
	40	25, 32, 40		562154	DHAA-D-L-40-G7-25	1
EGC/DFM	EGC	DFM	DHAA			
	80	12, 16, 20	2	562152	DHAA-D-L-25-G7-12	1
	120	25, 32, 40		562154	DHAA-D-L-40-G7-25	1


1) More information www.festo.com/x/topic/crc

2) Packaging unit.

Accessories

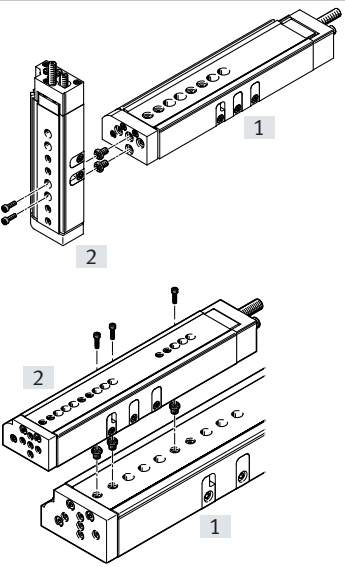
**Adapter kit
ZBH**

Material:
Wrought aluminium alloy
Free of copper and PTFE
RoHS-compliant

 **Note**
The kit includes the individual mounting interface as well as the necessary mounting material.

Permissible drive/drive combinations with adapter kit

Download CAD data → www.festo.com

Combination	[1] Drive Size	[2] Drive Size	Adapter kit		Quantity required	PU ²⁾	
			CRC ¹⁾	Part no. Type			
	DGSL	DGSL	2	–	M3x7 DIN 912³⁾	2	–
	4	4		8146543	ZBH-5-B⁴⁾	2	10
	6	4, 6		–	M3x10 DIN 912³⁾	2	–
	8, 10	4, 6		8146543	ZBH-5-B⁴⁾	2	10
	8, 10	8		548802	ZBV-M4-7	1	3
	10	10		–	M4x12 DIN 912³⁾	2	–
	10	10		8146544	ZBH-7-B⁴⁾	2	10
	12, 16	8, 10		548803	ZBV-M5-7	1	3
	12	12		–	M5x14 DIN 912³⁾	2	–
	12	12		8146544	ZBH-7-B⁴⁾	2	10
	16	12		–	M5x16 DIN 912³⁾	2	–
	16	12		8146544	ZBH-7-B⁴⁾	2	10
	16	16		–	M5x18 DIN 912³⁾	2	–
	16	16		8146544	ZBH-7-B⁴⁾	2	10
	20, 25	12, 16		548804	ZBV-M6-9	1	3
	20, 25	20		–	M6x20 DIN 912³⁾	2	–
20, 25	20	8137184	ZBH-9-B⁴⁾	2	10		
25	25	–	M6x30 DIN 912³⁾	2	–		
25	25	8137184	ZBH-9-B⁴⁾	2	10		

- 1) More information www.festo.com/x/topic/crc
- 2) Packaging unit.
- 3) The screws listed are not included in the scope of delivery of the drives.
- 4) The centring sleeves are included in the scope of delivery of the drives.

Accessories

Adapter kit HAPS, HMSV

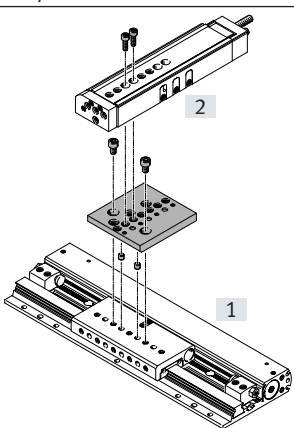
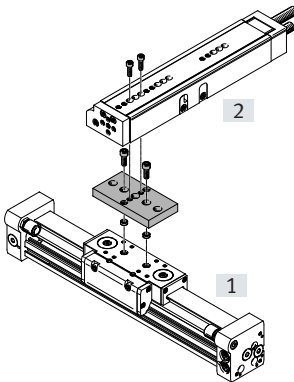
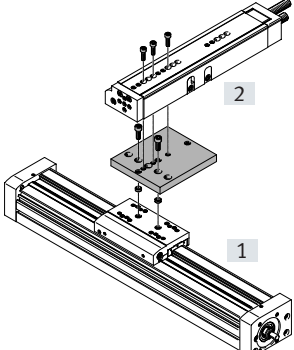
Material:
Wrought aluminium alloy
Free of copper and PTFE
RoHS-compliant



Note

The kit includes the individual mounting interface as well as the necessary mounting material.

Download CAD data → www.festo.com

Permissible drive/drive combinations with adapter kit							
Combination	[1] Drive Size	[2] Drive Size	Adapter kit CRC ¹⁾	Part no.	Type	Quantity required	PU ²⁾
	SLG	DGSL	HAPS				
	8, 12	4, 6	2	189533	HAPS-11	1	1
	12	8, 10		189534	HAPS-12	1	1
	18	8, 10, 12					
	DGC	DGSL	HMSV				
	8, 12	4, 6	2	548777	HMSV-47	1	1
	18	8, 10		548778	HMSV-48	1	1
	18	12, 16		189657	HMSV-41	1	1
	25	12, 16, 20, 25		548781	HMSV-51	1	1
	32, 40	20, 25		548780	HMSV-50	1	1
	DGE	DGSL	HMSV				
	25	12, 16, 20, 25	2	548781	HMSV-51	1	1
	40	20, 25		548780	HMSV-50	1	1

1) More information www.festo.com/x/topic/crc
2) Packaging unit.

Accessories

Adapter kit HMSV

Material:
Wrought aluminium alloy
Free of copper and PTFE
RoHS-compliant

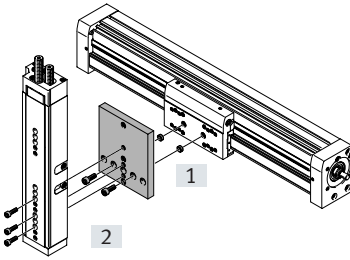
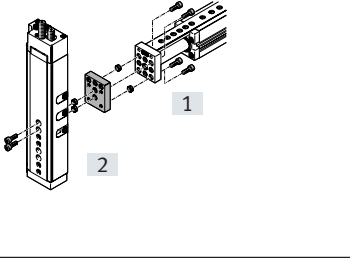
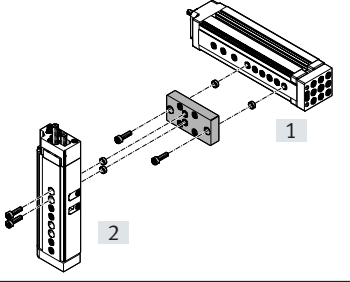


Note

The kit includes the individual mounting interface as well as the necessary mounting material.

Permissible drive/drive combinations with adapter kit

Download CAD data → www.festo.com

Combination	[1] Drive Size	[2] Drive Size	Adapter kit CRC ¹⁾		Type	Quantity required	PU ²⁾
			Part no.				
EGC/DGSL	EGC	DGSL	HMSV				
	50	4, 6	2	548777	HMSV-47	1	1
	70	8, 10		548778	HMSV-48	1	1
	70	12, 16		189657	HMSV-41	1	1
	80	12, 16, 20, 25		548781	HMSV-51	1	1
	120	20, 25		548780	HMSV-50	1	1
EGSL/DGSL	EGSL	DGSL	HMSV				
	35	4, 6, 8, 10	2	1088262	HMSV-70	1	–
	45, 55	8, 10		548803	ZBV-M5-7	1	3
	45	12, 16		–	M5x14 DIN 912 ³⁾	2	–
	55	12, 16		8146544	ZBH-7-B ⁴⁾	2	10
				–	M5x12 DIN 912 ³⁾	2	–
	75	12, 16		548804	ZBV-M6-9	1	3
	75	20		–	M6x20 DIN 912 ³⁾	2	–
	35	4, 6, 8, 10		8137184	ZBH-9-B ⁴⁾	2	10
1088327			HMSV-73	1	–		
	ELCC	DGSL	DHAA				
	60	8-50	2	5)	–	–	
	60	10-50		5)	–	–	
	70	12-80		5)	–	–	
	70	16-80		5)	–	–	
	90, 110	20-150		5)	–	–	
	90, 110	25-150		5)	–	–	

1) More information www.festo.com/x/topic/crc

2) Packaging unit.

3) The screws listed are not included in the scope of delivery of the drives.

 
4) The centring sleeves are included in the scope of delivery of the drives.

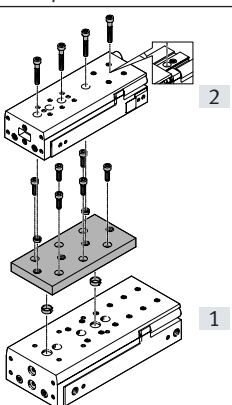
5) No adapter kit required as direct mounting is possible

Accessories

Adapter kit DHAA

Material:
Wrought aluminium alloy
Free of copper and PTFE
RoHS-compliant

 **Note**
The kit includes the individual mounting interface as well as the necessary mounting material.


Permissible drive/drive combinations with adapter kit				Download CAD data → www.festo.com		
Combination	[1] Drive Size	[2] Drive Size	Adapter kit			PU ²⁾
			CRC ¹⁾	Part no.	Type	
DGST/DGST	DGST	DGST	DHAA			
	6-10, 6-20	6-10	2	8161573	DHAA-D-G8-H-6-10-G8-6-10	1
	6-20	6-20		8161574	DHAA-D-G8-H-6-40-G8-6-30	1
	6-30	6-20, 6-30		8161581	DHAA-D-G8-H-8-10-G8-68-10	1
	6-40	6-30, 6-40		8161582	DHAA-D-G8-H-8-30-G8-68-20	1
	6-50	6-40, 6-50		8161581	DHAA-D-G8-H-8-10-G8-68-10	1
	8-10	6-10		8161582	DHAA-D-G8-H-8-30-G8-68-20	1
	8-20	6-10, 6-20		8161581	DHAA-D-G8-H-8-10-G8-68-10	1
	8-30	6-20, 6-30		8161582	DHAA-D-G8-H-8-30-G8-68-20	1
	8-40	6-30, 6-40		8161581	DHAA-D-G8-H-8-10-G8-68-10	1
	8-10	8-10		8161582	DHAA-D-G8-H-8-30-G8-68-20	1
	8-20	8-10, 8-20		8161580	DHAA-D-G8-H-8-50-G8-68-40	1
	8-30	8-20, 8-30		8161664	DHAA-D-G8-H-10-10-G8-8-10	1
	8-40	8-30, 8-40		8161665	DHAA-D-G8-H-10-40-G8-8-30	1
	8-50	8-40, 8-50		8161666	DHAA-D-G8-H-10-80-G8-8-50	1
	8-80	8-50, 8-80		8161911	DHAA-D-G8-H-10-10-G8-10-10	1
	10-10	8-80		8161912	DHAA-D-G8-H-10-40-G8-10-30	1
	10-10	10-10		8161910	DHAA-D-G8-H-10-80-G8-10-50	1
	10-20	10-10, 10-20		8161934	DHAA-D-G8-H-12-10-G8-10-10	1
	10-30	10-20, 10-30		8161936	DHAA-D-G8-H-12-40-G8-10-30	1
	10-40	10-30, 10-40		8161937	DHAA-D-G8-H-12-50-G8-10-40	1
	10-50	10-40, 10-50		8161939	DHAA-D-G8-H-12-80-G8-10-50	1
	10-80	10-50, 10-80		8161935	DHAA-D-G8-H-12-10-G8-12-10	1
	10-100	10-80, 10-100		8161933	DHAA-D-G8-H-12-40-G8-12-30	1
	12-10	12-10		8161940	DHAA-D-G8-H-12-50-G8-12-40	1
	12-20	12-10, 12-20		8161938	DHAA-D-G8-H-12-80-G8-12-50	1
	12-30	12-20, 12-30				
	12-40	12-30, 12-40				
	12-50	12-40, 12-50				
	12-80	12-50, 12-80				
	12-100	12-80, 12-100				

1) More information www.festo.com/x/topic/crc
2) Packaging unit.

Accessories

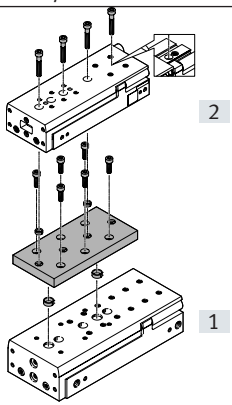
**Adapter kit
DHAA**

Material:
Wrought aluminium alloy
Free of copper and PTFE
RoHS-compliant

 **Note**
The kit includes the individual mounting interface as well as the necessary mounting material.

Permissible drive/drive combinations with adapter kit

Download CAD data → www.festo.com

 
Combination	[1] Drive Size	[2] Drive Size	Adapter kit			PU ²⁾	
			CRC ¹⁾	Part no.	Type		
DGST/DGST	DGST	DGST	DHAA				
	16-10	12-10	2	8161925	DHAA-D-G8-H-16-10-G8-12-10	1	
	16-20	12-10, 12-20					
	16-30	12-20, 12-30					
	16-40	12-30, 12-40					
	16-50	12-40, 12-50					
	16-80	12-50, 12-80					
	16-100	12-80, 12-100					
	16-10	16-10			8161918	DHAA-D-G8-H-16-10-G8-16-10	1
	16-20	16-10, 16-20					
	16-30	16-20, 16-30					
	16-40	16-30, 16-40					
	16-50	16-40, 16-50			8161919	DHAA-D-G8-H-16-50-G8-16-40	1
	16-80	16-50, 16-80					
	16-100	16-80, 16-100			8161920	DHAA-D-G8-H-16-100-G8-16-80	1
	16-125	16-100, 16-125			8161917	DHAA-D-G8-H-16-125-G8-16-100	1
	16-150	16-125, 16-150					
	20-10	16-10			8161233	DHAA-D-G8-H-20-10-G8-16-10	1
	20-20	16-10, 16-20					
	20-30	16-20, 16-30					
	20-40	16-30, 16-40					
	20-50	16-40, 16-50					
	20-80	16-50, 16-80			8161232	DHAA-D-G8-H-20-80-G8-16-50	1
	20-100	16-80, 16-100					
	20-125	16-100, 16-125			8161234	DHAA-D-G8-H-20-125-G8-16-100	1
	20-150	16-125, 16-150					
	20-200	16-150					
	20-10	20-10			8161370	DHAA-D-G8-H-20-10-G8-20-10	1
	20-20	20-10, 20-20					
	20-30	20-20, 20-30					
	20-40	20-30, 20-40					
	20-50	20-40, 20-50					
	20-80	20-50, 20-80			8161371	DHAA-D-G8-H-20-80-G8-20-50	1
	20-100	20-80, 20-100					
20-125	20-100, 20-125			8161372	DHAA-D-G8-H-20-125-G8-20-100	1	
20-150	20-125, 20-150						
20-200	20-150, 20-200			8161369	DHAA-D-G8-H-20-200-G8-20-150	1	
25-10	20-10			8161381	DHAA-D-G8-H-25-10-G8-20-10	1	
25-20	20-10, 20-20						
25-30	20-20, 20-30						
25-40	20-30, 20-40						
25-50	20-40, 20-50						

1) More information www.festo.com/x/topic/crc
2) Packaging unit.

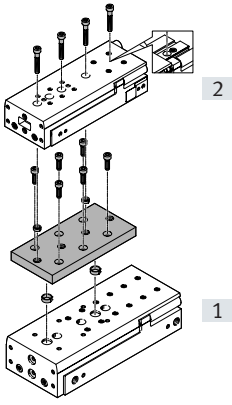
Accessories

Adapter kit DHAA

Material:
Wrought aluminium alloy
Free of copper and PTFE
RoHS-compliant

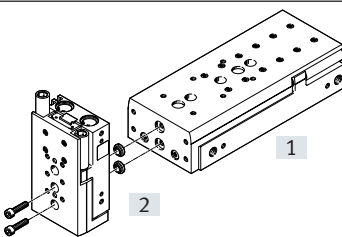
 **Note**
The kit includes the individual mounting interface as well as the necessary mounting material.

Permissible drive/drive combinations with adapter kit Download CAD data → www.festo.com

Combination	[1] Drive Size	[2] Drive Size	Adapter kit			PU ²⁾
			CRC ¹⁾	Part no.	Type	
DGST/DGST	DGST	DGST	DHAA			
	25-80	20-50, 20-80	2	8161382	DHAA-D-G8-H-25-80-G8-20-50	1
	25-100	20-80, 20-100		8161383	DHAA-D-G8-H-25-125-G8-20-100	1
	25-125	20-100, 20-125		8161384	DHAA-D-G8-H-25-200-G8-20-150	1
	25-150	20-125, 20-150				
	25-200	20-150, 20-200		8161386	DHAA-D-G8-H-25-10-G8-25-10	1
	25-10	25-10				
	25-20	25-10, 25-20		8161387	DHAA-D-G8-H-25-80-G8-25-50	1
	25-30	25-20, 25-30				
	25-40	25-30, 25-40				
	25-50	25-40, 25-50		8161388	DHAA-D-G8-H-25-125-G8-25-100	1
	28-80	25-50, 25-80				
	25-100	25-80, 25-100				
	25-125	25-100, 25-125		8161385	DHAA-D-G8-H-25-200-G8-25-150	1
	25-150	25-125, 25-150				
25-200	25-150, 25-200					

- 1) More information www.festo.com/x/topic/crc
2) Packaging unit.

Permissible drive/drive combinations without/with adapter kit Download CAD data → www.festo.com

 
Combination	[1] Drive Size	[2] Drive Size	Adapter kit			Quantity required	PU ²⁾
			CRC ¹⁾	Part no.	Type		
DGST/DGST	DGST	DGST					
	Without adapter kit		Screw and centring sleeve				
	8	6	-		M3x14	2	-
	10	6		8146543	ZBH-5-B	2	1
					M3x14	2	-
	10	8		8146543	ZBH-5-B	2	1
					M3x18	2	-
	12, 16	10		8146543	ZBH-5-B	2	1
					M4x22	2	-
	16	12		8146544	ZBH-7-B	2	1
					M4x27	2	-
	20	16		8146544	ZBH-7-B	2	1
					M5x30	2	-
	25	20		548806	ZBV-12-9	2	1
					M6x40	2	-
		8137185		ZBH-12-B	2	1	
With adapter kit		DHAA					
12	8	2	8167641	DHAA-D-G8-12-G8-8	1	1	
20	12		8167640	DHAA-D-G8-20-G8-12	1	1	
25	16		8167639	DHAA-D-G8-25-G8-16	1	1	

- 1) More information www.festo.com/x/topic/crc
2) Packaging unit.

Accessories

Adapter kit DHAA

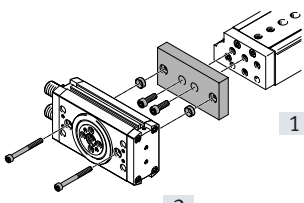
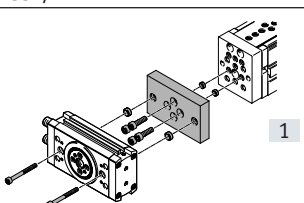
Material:
Wrought aluminium alloy
Free of copper and PTFE
RoHS-compliant



Note
The kit includes the individual mounting interface as well as the necessary mounting material.

Permissible drive/drive combinations with adapter kit

Download CAD data → www.festo.com

Combination	[1] Drive Size	[2] Drive Size	Adapter kit			PU ³⁾	
			CRC ¹⁾	Part no.	Type		
DGSL/DRRD	DGSL	DRRD	DHAA				
	4	8	2	2767489	DHAA-D-G6-4-Q11-8	1	
	6	8		2762930	DHAA-D-G6-6-Q11-8	1	
	8, 10	10		2737394	DHAA-D-G6-8/10-Q11-10	1	
	12, 16	10		2737247	DHAA-D-G6-12/16-Q11-10	1	
	8, 10	12		2736429	DHAA-D-G6-8/10-Q11-12	1	
	12	12		2782718	DHAA-D-G6-12-Q11-12	1	
	16	12		2734418	DHAA-D-G6-16-Q11-12	1	
	20	16		1917841	DHAA-D-G6-20-Q11-16	1	
	20, 25	20		1916912	DHAA-D-G6-20/25-Q11-20	1	
	25	25		1707360	DHAA-D-G6-25-Q11-25	1	
	DGSL	DRRD-....P...E...²⁾		DHAA			
	20	16		2	2332271	DHAA-D-G6-20-Q11-16-E	1
	20, 25	20			2332452	DHAA-D-G6-20/25-Q11-20-E	1
	25	25			2332584	DHAA-D-G6-25-Q11-25-E	1
EGSL/DRRD	EGSL	DRRD	DHAA				
	35	8	2	2730033	DHAA-D-E8-35-Q11-8	1	
	35	10		2729506	DHAA-D-E8-35-Q11-10	1	
	45	10		2728486	DHAA-D-E8-45-Q11-10	1	
	35	12		2719384	DHAA-D-E8-35-Q11-12	1	
	45, 55	12		2715152	DHAA-D-E8-45/55-Q11-12	1	
	55	16		1926914	DHAA-D-E8-55-Q11-16	1	
	75	16		1928306	DHAA-D-E8-75-Q11-16	1	
	75	20		1930038	DHAA-D-E8-75-Q11-20	1	
	EGSL	DRRD-....P...E...²⁾		DHAA			
	55	16		2	2279410	DHAA-D-E8-55-Q11-16-E	1
	75	16			2279453	DHAA-D-E8-75-Q11-16-E	1
	75	20			2279473	DHAA-D-E8-75-Q11-20-E	1

1) More information www.festo.com/x/topic/crc


2) With energy through-feed

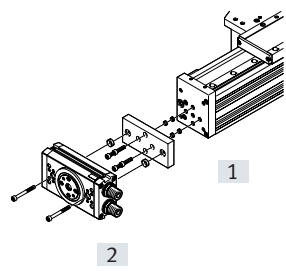
3) Packaging unit.

Accessories

Adapter kit DHAA

Material:
Wrought aluminium alloy
Free of copper and PTFE
RoHS-compliant

 **Note**
The kit includes the individual mounting interface as well as the necessary mounting material.

Permissible drive/drive combinations with adapter kit			Download CAD data → www.festo.com				
Combination	[1] Drive Size	[2] Drive Size	Adapter kit CRC ¹⁾	Part no.	Type	PU ³⁾	
	ELCC	DRRD	DHAA				
	60	10	2	2737394	DHAA-D-G6-8/10-Q11-10	1	
	60	12		2736429	DHAA-D-G6-8/10-Q11-12	1	
	60	16		1675259	DHAA-D-E2-18-Q11-16	1	
	60, 70	20		1679833	DHAA-D-E2-18/25-Q11-20	1	
	60, 70	25		1696421	DHAA-D-E2-25-Q11-25	1	
	70	32		1702297	DHAA-D-E2-25-Q11-32	1	
	70, 90	32		5154625	DHAA-D-E21-70...110-Q11-32	1	
	70, 90	35		5154627	DHAA-D-E21-70...110-Q11-35	1	
	90, 110	40		5154629	DHAA-D-E21-70...110-Q11-40	1	
	90, 110	50		5154639	DHAA-D-E21-70...110-Q11-50	1	
	110	63		5154642	DHAA-D-E21-70...110-Q11-63	1	
	ELCC	DRRD-...-P...E...²⁾	DHAA				
	60	16	2	2328624	DHAA-D-E2-18-Q11-16-E	1	
	60, 70	20		2328779	DHAA-D-E2-18/25-Q11-20-E	1	
	60, 70	25		2328793	DHAA-D-E2-25-Q11-25-E	1	
	70	32		2328805	DHAA-D-E2-25-Q11-32-E	1	
	70, 90	32		5154626	DHAA-D-E21-70...110-Q11-32-E	1	
	70, 90	35		5154628	DHAA-D-E21-70...110-Q11-35-E	1	
	90, 110	40		5154630	DHAA-D-E21-70...110-Q11-40-E	1	
	90, 110	50		5154640	DHAA-D-E21-70...110-Q11-50-E	1	
	110	63		5154643	DHAA-D-E21-70...110-Q11-63-E	1	


1) More information www.festo.com/x/topic/crc
 2) With energy through-feed
 3) Packaging unit.

Adapter for semi-rotary drives DRRD

Accessories

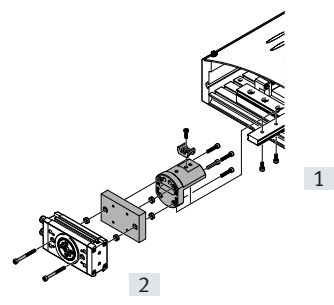
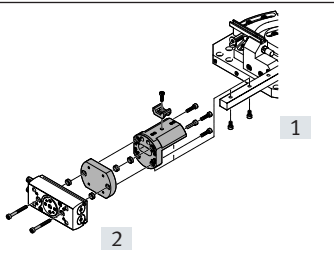
Adapter kit DHAA

Material:
Wrought aluminium alloy
Free of copper and PTFE
RoHS-compliant

 **Note**
The kit includes the individual mounting interface as well as the necessary mounting material.

Permissible drive/drive combinations with adapter kit

Download CAD data → www.festo.com

Combination	[1] Drive Size	[2] Drive Size	Adapter kit CRC ¹⁾		Type	PU ⁴⁾
			Part no.			
HSP/DRRD	HSP	DRRD	DHAA			
	12	8	2	2786084	DHAA-D-H4-12-Q11-8	1
			–	540881	HAPG-70-B	1
	16	10	2	2785801	DHAA-D-H4/H5-12/16-Q11-10	1
			–	540882	HAPG-71-B	1
	16	12	2	2784113	DHAA-D-H4/H5-16/25-Q11-12	1
			–	540882	HAPG-71-B	1
	25	12	2	2784113	DHAA-D-H4/H5-16/25-Q11-12	1
			–	540883	HAPG-72-B ³⁾	1
	25	16	2	1919910	DHAA-D-H4-25-Q11-16	1
			–	540883	HAPG-72-B ³⁾	1
HSP	DRRD-...-P...E...²⁾	DHAA				
25	16	2	2284940	DHAA-D-H4-25-Q11-16-E	1	
		–	540883	HAPG-72-B ³⁾	1	
HSW/DRRD	HSW	DRRD	DHAA			
	10	8	2	2789655	DHAA-D-H5-10-Q11-8	1
			–	540249	HAPG-69	1
	12	8	2	2788114	DHAA-D-H5-12-Q11-8	1
			–	540882	HAPG-71-B	1
	12	10	2	2785801	DHAA-D-H4/H5-12/16-Q11-10	1
			–	540882	HAPG-71-B	1
	16	10	2	2785801	DHAA-D-H4/H5-12/16-Q11-10	1
			–	540882	HAPG-71-B	1
16	12	2	2784113	DHAA-D-H4/H5-16/25-Q11-12	1	
		–	540882	HAPG-71-B	1	

1) More information www.festo.com/x/topic/crc
 2) With energy through-feed
 3) The centring sleeves for attaching to the adapter kit HAPG-72-B are not required.
 4) Packaging unit.

Accessories

Adapter kit HAPS

Material:
Wrought aluminium alloy
Free of copper and PTFE
RoHS-compliant

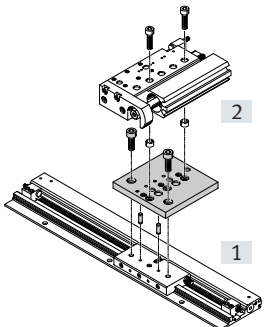


Note

The kit includes the individual mounting interface as well as the necessary mounting material.

Download CAD data → www.festo.com

Permissible drive/drive combinations with adapter kit

Combination	[1] Drive Size	[2] Drive Size	Adapter kit			PU ²⁾
			CRC ¹⁾	Part no.	Type	
SLG/SLF	SLG	SLF	HAPS			
	8, 12	6, 10	2	189533	HAPS-11	1
	12	16		189533	HAPS-11	1
	18	10, 16		189534	HAPS-12	1


- 1) More information www.festo.com/x/topic/crc
- 2) Packaging unit.

Adapter for twin cylinders DPZ/DPZJ

Accessories

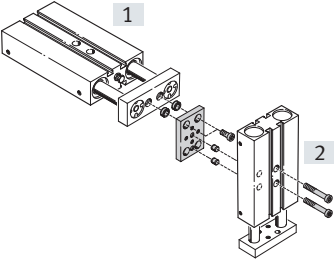
Adapter kit BPL

Material:
Wrought aluminium alloy
Free of copper and PTFE
RoHS-compliant

 **Note**
The kit includes the individual mounting interface as well as the necessary mounting material.

Permissible drive/drive combinations with adapter kit

Download CAD data → www.festo.com

Combination	[1] Drive Size	[2] Drive Size	Adapter kit			
			CRC ¹⁾	Part no.	Type	PU ²⁾
DPZ/DPZ	DPZ	DPZ	BPL			
	20, 25, 32	10, 16	2	150929	BPL-1	1
	20, 25, 32	20		150930	BPL-2	1
	25, 32	25		150931	BPL-3	1
	32	32		150931	BPL-3	1

1) More information www.festo.com/x/topic/crc
2) Packaging unit.