


CPX | VTSA-CB configuration in TIA

Terminal configuration – Zone and standard valves

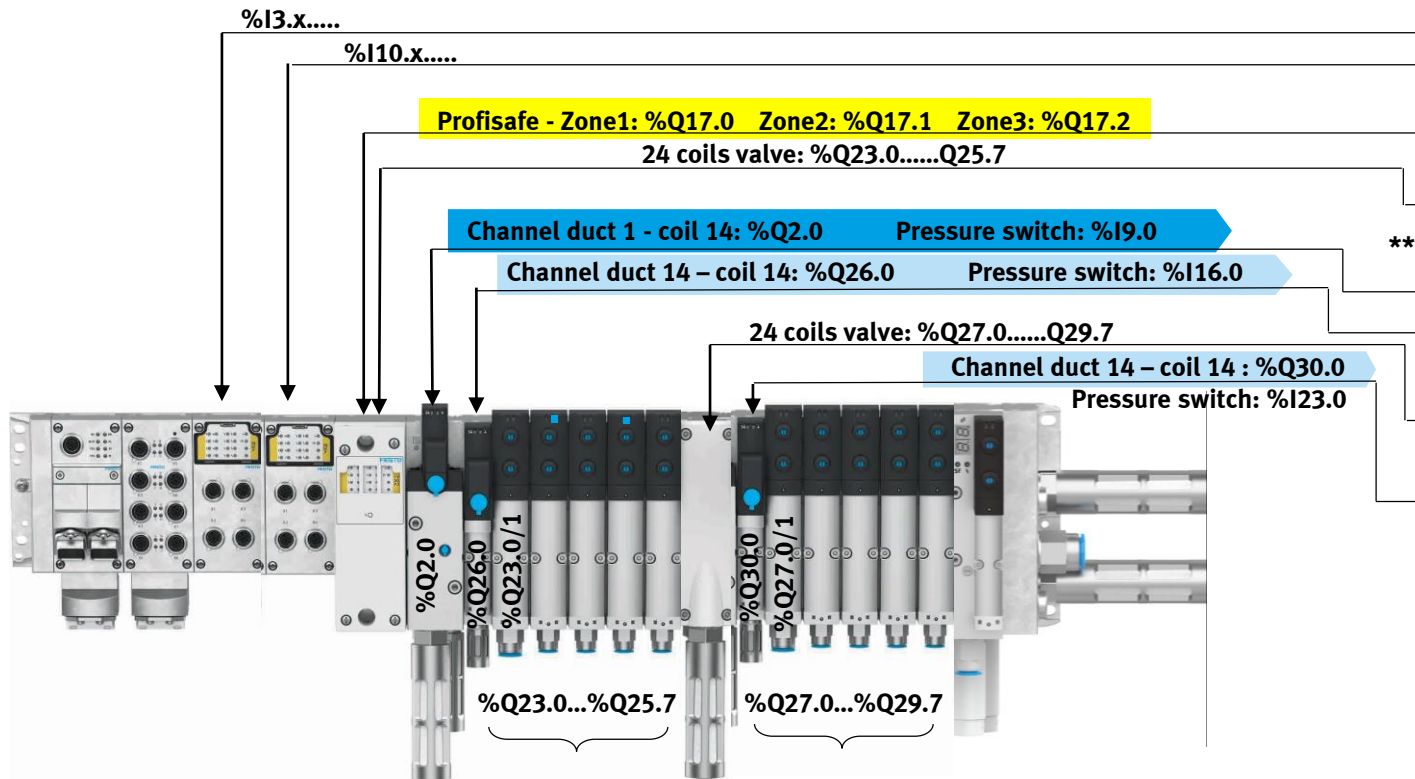

Device overview					
Module	...	Rack	Slot	I address	Q address
▼ CPX		0	0		
▶ PN-IO Interface		0	0 X1		
FB34 PNIO Modul [Status]_1		0	1	68	
8DI-D [8DE]_1		0	2	2	
F8DI-P Word [8DE-F]_1	■	0	3	3...8	3...9
F8DI-P Word [8DE-F]_2	■	0	4	10...15	10...16
▼ VTSA-CB-IS_1		0	5		
VTSA-CB-IS	■	0	5 PRO...	17...22	17...22
VTSA-CB 24 spulen		0	5 Valv...		23...25
Valve diagnosis		0	5 Inp...	29...31	
VABV-1Q-CB_1		0	6	9	2
VABV-12HS-T5_1		0	7	16	26
▼ VABF-CB1_1		0	8		27...29
VABF-CB1		0	8 Valv...		27...29
		0	8 Inp...		
VABV-2HS-T5_1		0	9	23	30
VABF-V2B1-CB SPS Modus_1		0	10	24...28	31...35

** Option for diagnosis via EA cycling date of the interface.
If you not need this function, just leave it blank.