


**Axial kit**  
**EAMM-A-D32-42A-S1**  
Part number: 1322179

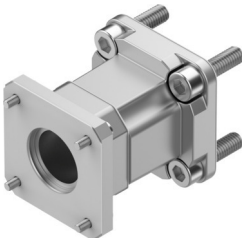

**Data sheet**

| Feature                  | Value                  |
|--------------------------|------------------------|
| Nominal length           | 49.5 mm                |
| Mounting position        | optional               |
| Max. rotational speed    | 10000 rpm              |
| LABS (PWIS) conformity   | VDMA24364 zone III     |
| Storage temperature      | -25 °C...60 °C         |
| Relative air humidity    | 0 - 95%                |
| Degree of protection     | IP65                   |
| Ambient temperature      | -10 °C...60 °C         |
| Mass moment of inertia   | 0.28 kgmm <sup>2</sup> |
| Transmittable torque     | 1.1 Nm                 |
| Product weight           | 140 g                  |
| Interface code, actuator | D32                    |
| Interface code, motor in | 42A                    |
| Note on materials        | RoHS-compliant         |