


End plate kit NEV-1DA/DB-NPT

Part number: 13996

FESTO

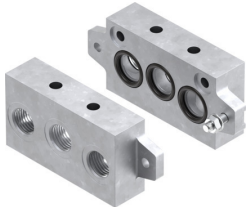

Data sheet

Feature	Value
Width	110 mm
Operating pressure	0 bar...16 bar
Operating medium	Compressed air to ISO 8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible (in which case lubricated operation will always be required)
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Media temperature	-10 °C...60 °C
Ambient temperature	-10 °C...60 °C
Mounting method for sub-base	With through-hole
Mounting method for valve	Screw-in
Pneumatic connection, port 1	NPT3/8-18
Pneumatic connection, port 3	NPT3/8-18
Pneumatic connection, port 5	NPT3/8-18