


Linear drive
DGO-1 5/8"- -PPV-A-B
Part number: 15232

FESTO

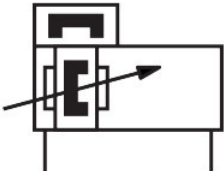

Data sheet

Feature	Value
Stroke	0.04 in...157 in
Piston diameter	1 5/8"
Cushioning	Pneumatic cushioning, adjustable at both ends
Guide	Plain-bearing guide
Coupling design	Force-locking (magnetic)
Operating pressure	1.3 bar...7 bar
Mode of operation	Double-acting
Operating medium	Compressed air to ISO 8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible (in which case lubricated operation will always be required)
LABS (PWIS) conformity	VDMA24364-B2-L
Ambient temperature	-20 °C...60 °C
Cushioning length	23 mm
Pneumatic connection	1/4 NPT