


# Connecting cable KMP1-02-II-8-X

Part number: 158989  
Product to be discontinued

**FESTO**

The cable is available in lengths from 1 to 99 m.

Type to be discontinued. Available until 2017. See Support Portal for alternative products.

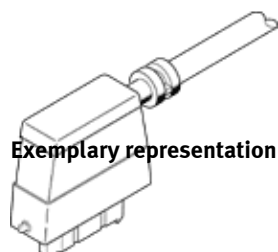

**Exemplary representation**

## Data sheet

| Feature                                              | Value                         |
|------------------------------------------------------|-------------------------------|
| Assembly position                                    | Any                           |
| Operating voltage range AC                           | ≤ 300 V                       |
| Operating voltage range DC                           | ≤ 250 V                       |
| Permissible current load                             | 4 A                           |
| Protection class                                     | IP65                          |
| Ambient temperature with flexible cable installation | 5 ... 70 °C                   |
| Ambient temperature                                  | -30 ... 70 °C                 |
| Electrical connection                                | 40-pin<br>Plug socket         |
| Cable structure                                      | 39 x 0,75 mm <sup>2</sup>     |
| Cable diameter                                       | 17 mm                         |
| Mounting type                                        | With clamp strap              |
| Materials information, housing                       | Die-cast light alloy          |
| Materials information, cable sheaths                 | PE                            |
| Material information for crimp connectors            | Silver plated<br>Copper alloy |