


 
Linear drive DGP-2 1 1/2"- -PPV-A-B

Part number: 160914

FESTO

For proximity sensing, rodless, with positive-locking connection between piston and driver and adjustable end-position cushioning at both ends.

This product is only available if ordered from the Festo Corporation, USA.
Type to be discontinued. Available until 2013.

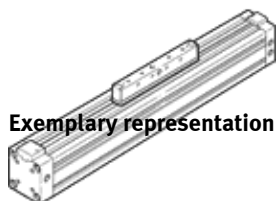

Exemplary representation

Data sheet

Feature	Value
Stroke	10 ... 3,000 mm
Piston diameter	2 1/2"
Cushioning	PPV: Pneumatic cushioning adjustable at both ends YXR: Shock absorber, hard characteristic curve
Guide	Basic guide
Driver principle	positive-locking (slot)
Operating pressure	1.5 ... 8 bar
Mode of operation	double-acting
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Corrosion resistance classification CRC	2
Ambient temperature	-10 ... 60 °C
Cushioning length	30 mm
Pneumatic connection	NPT3/8-18