

 

Non-return valve HGL-M5

Part number: 161779

FESTO

With sealing ring OL.

Discontinued, available through 2006

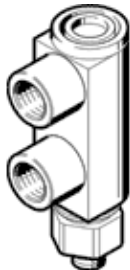

Data sheet

Feature	Value
Valve function	piloted non-return function
Pneumatic connection, port 1	M5
Pneumatic connection, port 2	M5
Mounting type	Threaded
Standard nominal flow rate	108 l/min
Operating pressure	0.5 ... 10 bar
Operating medium	Dried, filtered compressed air Dried, filtered and lubricated compressed air
Ambient temperature	-10 ... 60 °C
Materials information, housing	Zinc die-casting
Medium temperature	-10 ... 60 °C
Max. tightening torque	1.5 Nm
Product weight	20 g
Pilot air port 21	M5
Materials information for screw-in stud	Steel
Materials information for seals	NBR