


flow control valve GRGO-M3-QS-3

Part number: 175045
Product to be discontinued

FESTO

Acts in both directions of flow. With QS push-in fitting.
Type to be discontinued. Available until 2018. See Support Portal for alternative products.

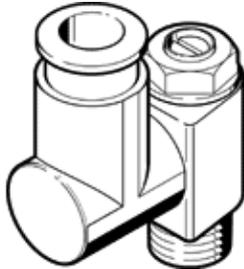

Data sheet

Feature	Value
Valve function	Throttle function
Pneumatic connection, port 1	M3
Pneumatic connection, port 2	QS-3
Adjusting element	Slotted head screw
Mounting type	Threaded
Standard nominal flow rate in flow control direction	41 l/min
Operating pressure	0 ... 10 bar
Ambient temperature	-10 ... 60 °C
Assembly position	Any
Standard flow rate in direction of flow control: 6 → 0 bar	95 l/min
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:4:4]
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
Medium temperature	-10 ... 60 °C
Max. tightening torque	0.3 Nm
Product weight	14 g
Material of threaded plug	Brass
Materials note	Conforms to RoHS
Material seals	NBR
Material release ring	POM
Material adjusting screw	Brass
Material swivel fitting	Zinc die-casting