


# Connecting cable KMYZ-2-24-M8-2,5-LED

Part number: 177678

**FESTO**

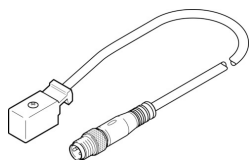

## Data sheet

Feature	Value
Switching position indicator	LED
Type of mounting	On solenoid valve via self-tapping screw
Mounting position	optional
Product weight	54 g
Electrical connection	2-pin/3-pin Angled socket/straight plug Square design/M8x1
Nominal operating voltage DC	24 V
Current rating at 40° C	1 A
Protective conductor connection	Not available
Cable length	2.5 m
Cable characteristic	Standard
Cable diameter	3.4 mm
Cable structure	2 x 0.25 mm <sup>2</sup>
Degree of protection	IP65
Ambient temperature	-10 °C...50 °C
CE mark (see declaration of conformity)	In accordance with EU RoHS Directive
UKCA marking (see declaration of conformity)	To UK RoHS instructions
LABS (PWIS) conformity	VDMA24364-B2-L
Note on materials	RoHS-compliant
Corrosion resistance class CRC	2 - Moderate corrosion stress
Material cable sheath	TPE-U(PUR)
Material housing	PA
Material seals	TPE-O
Material electrical contact	Bronze
Material threaded sleeve	Nickel-plated brass