


Vacuum filter ESF-4A

Part number: 191203

FESTO

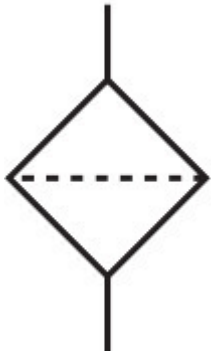

Data sheet

Feature	Value
Mounting position	optional
Grade of filtration	10 µm
Operating pressure	-0.95 bar...4 bar
Flow rate with vacuum = -0.075 MPa (-0.75 bar, -10.875 psi)	260 l/min
Operating medium	Atmospheric air based on ISO 8573-1:2010 [7:::-]
Corrosion resistance class CRC	1 - Low corrosion stress
LABS (PWIS) conformity	VDMA24364-A1-L
Ambient temperature	0 °C...60 °C
Product weight	19 g
Type of mounting	Via male thread Via vacuum port
Pneumatic connection	M6
Vacuum connection	M6
Note on materials	RoHS-compliant
Material seals	NBR
Material filter	PVF
Material housing	Aluminium Brass, nickel-plated