


# Standard cylinder DNA-1 1/2"- -

Part number: 193383

FESTO

This product is only available if ordered from the Festo Corporation, USA.  
Depending on the configuration, the illustrations, the technical data on the data sheet and the relevant accessories might not exactly match this product.

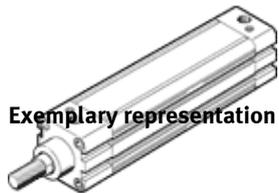

## Data sheet

~ConfIndependentDatasheet

Feature	Value
Stroke	0.5 ... 80 "
Piston diameter	1 1/2"
Based on the standard	ANSI/NFPA
Operating pressure	0.6 ... 12 bar
Mode of operation	double-acting
Operating medium	Filtered compressed air
Corrosion resistance classification CRC	1
Ambient temperature	≥ -20 °C
Additional mass factor per 10 mm of stroke	250 g
Materials information for cover	Wrought Aluminium alloy
Materials information, housing	Wrought Aluminium alloy
Materials information for piston rod	High alloy steel