


Plug socket with cable KMF-1-24-10-LED

Part number: 193458

FESTO

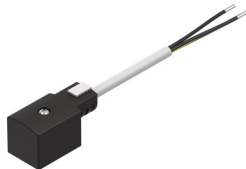

Data sheet

Feature	Value
Switching position indicator	LED
Type of mounting	On solenoid valve via M3 central screw
Mounting position	optional
Product weight	620 g
Electrical connection	Socket
Nominal operating voltage DC	24 V
Protective conductor connection	Available
Cable length	10 m
Cable diameter	6 mm
Cable structure	3 x 0.75 mm ²
Degree of protection	IP67 To IEC 60529
Ambient temperature	-20 °C...80 °C
CE mark (see declaration of conformity)	In accordance with EU RoHS Directive
UKCA marking (see declaration of conformity)	To UK RoHS instructions
LABS (PWIS) conformity	VDMA24364-B2-L
Material cable sheath	PVC
Material housing	PC POM
Material electrical contact	Bronze