


**Manifold**  
**MHA1-PR6-3-M3-PI**  
Part number: 197 224

**FESTO**

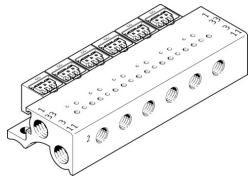

**Data sheet**

Feature	Value
Max. number of valve positions	6
Operating pressure	0 bar...8 bar
Operating medium	Compressed air to ISO 8573-1:2010 [7:4:4]
Note on operating and pilot medium	Lubricated operation possible (in which case lubricated operation will always be required)
Corrosion resistance class CRC	1 - Low corrosion stress
LABS (PWIS) conformity	VDMA24364-B2-L
Ambient temperature	-10 °C...60 °C
Mounting method for sub-base	With through-hole
Mounting method for valve	Via female thread
Pneumatic connection, port 1	M7
Pneumatic connection, port 2	M3
Pneumatic connection, port 3	M7
Material sub-base	Wrought aluminium alloy