


**Clevis foot**  
**LBG-32-R3**  
Part number: 2078790

**FESTO**

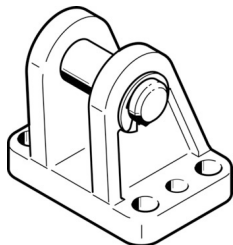

**Data sheet**

Feature	Value
Size	32
Mounting position	optional
Corrosion resistance class CRC	3 - high corrosion stress
LABS (PWIS) conformity	VDMA24364-B2-L
Suitability for the production of Li-ion batteries	Metals with more than 5% by mass of copper, zinc or nickel by mass are excluded from use. Exceptions are nickel in steel, chemically nickel-plated surfaces, printed circuit boards, cables, electrical plug connectors and coils
Ambient temperature	-40 °C...150 °C
Max. load capacity	0.9 kN
Product weight	220 g
Note on materials	RoHS-compliant
Material mounting	High-alloy stainless steel
Material bolt	High-alloy stainless steel
Material lock	High-alloy stainless steel