


Clevis foot
LBG-50-R3
Part number: 2078794

FESTO

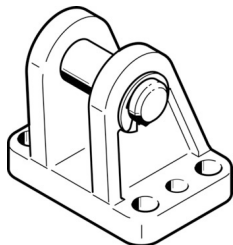

Data sheet

Feature	Value
Size	50
Mounting position	optional
Corrosion resistance class CRC	3 - high corrosion stress
LABS (PWIS) conformity	VDMA24364-B2-L
Suitability for the production of Li-ion batteries	Metals with more than 5% by mass of copper, zinc or nickel by mass are excluded from use. Exceptions are nickel in steel, chemically nickel-plated surfaces, printed circuit boards, cables, electrical plug connectors and coils
Ambient temperature	-40 °C...150 °C
Max. load capacity	2.5 kN
Product weight	540 g
Note on materials	RoHS-compliant
Material mounting	High-alloy stainless steel
Material bolt	High-alloy stainless steel
Material lock	High-alloy stainless steel