


# Clevis foot LBG-100-R3

Part number: 2078799

FESTO

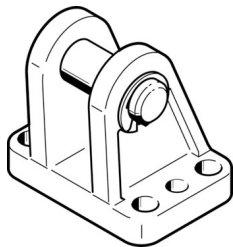

## Data sheet

| Feature  | Value   |
|--|---|
| Size   | 100   |
| Mounting position                                  | optional  |
| Corrosion resistance class CRC                     | 3 - high corrosion stress   |
| LABS (PWIS) conformity                             | VDMA24364-B2-L  |
| Suitability for the production of Li-ion batteries | Metals with more than 5% by mass of copper, zinc or nickel by mass are excluded from use. Exceptions are nickel in steel, chemically nickel-plated surfaces, printed circuit boards, cables, electrical plug connectors and coils |
| Ambient temperature                                | -40 °C...150 °C   |
| Max. load capacity                                 | 9 kN  |
| Product weight                                     | 1375 g  |
| Note on materials                                  | RoHS-compliant  |
| Material mounting                                  | High-alloy stainless steel  |
| Material bolt                                      | High-alloy stainless steel  |
| Material lock                                      | High-alloy stainless steel  |