


Flanged pressure gauge FMA-63-0,25-C

Part number: 225783

FESTO

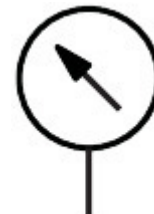

Data sheet

| Feature | Value |
|------------------------------------|--|
| Indicating range | 0 bar...0.25 bar 0 psi...3.6 psi |
| Conforms to standard | EN 837-3 |
| Nominal size of pressure gauge | 63 |
| Explosion protection | The information in the certificate must be observed! Zone 1 (ATEX) Zone 2 (ATEX) Zone 21 (ATEX) Zone 22 (ATEX) |
| Type of mounting | Front panel mounting |
| Operating medium | Liquid media Gaseous media |
| Note on operating and pilot medium | No acetylene No oxygen |
| Operating pressure | 0 bar...0.25 bar |
| Alternating load factor | 0.9 |
| Continuous load factor | 0.75 |
| Measurement accuracy class | 1.6 |
| Degree of protection | IP43 |
| Media temperature | -20 °C...80 °C |
| Ambient temperature | -20 °C...60 °C |
| LABS (PWIS) conformity | VDMA24364-B1/B2-L |
| Position of connection | Centred, rear side |
| Pneumatic connection | G1/4 |
| Material screwed plug | Brass |
| Material housing | Steel |
| Material screen | PMMA |
| Material mounting ring | Steel |
| Material screws | Steel |
| Product weight | 120 g |