


Sub-base
VABP-S1-2V1G-G38-2M-A1
Part number: 2738672

FESTO

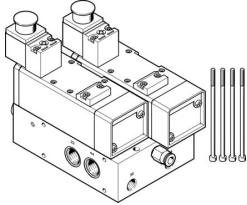

Data sheet

Feature	Value
Construction width	54 mm
Function port 32	G1/4
Function port 34	G1/4
Pneumatic port 22	Sub-base G3/8
Pneumatic port 44	Sub-base G3/8
Mounting position	optional
Operating pressure	0 bar...16 bar
Pilot pressure	3 bar...8 bar
Standard nominal flow rate (standardised to DIN 1343)	2000 l/min
Operating medium	Compressed air to ISO 8573-1:2010 [6:4:4]
Corrosion resistance class CRC	0 - No corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Media temperature	0 °C...50 °C
Ambient temperature	0 °C...50 °C
Product weight	3400 g
Pilot air port 14	G1/8
Pneumatic connection, port 2	G3/8
Pneumatic connection, port 4	G3/8
Note on materials	RoHS-compliant
Material manifold rail	Wrought aluminium alloy
Material o-ring	NBR
Material screws	Steel