


Distributor block FR-4-1/4

Part number: 2960

FESTO

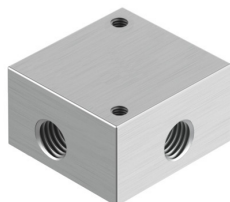

Data sheet

Feature	Value
Nominal size	11.5 mm
Mounting position	optional
Operating pressure complete temperature range	0 bar...16 bar
Operating medium	Compressed air to ISO 8573-1:2010 [7:...]
Note on operating and pilot medium	Lubricated operation possible (in which case lubricated operation will always be required)
Corrosion resistance class CRC	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Ambient temperature	-10 °C...80 °C
Product weight	68 g
Number of outputs	3
Number of supply lines	1
Pneumatic connection, port 1	Female thread G1/4
Pneumatic connection, port 2	Female thread G1/4
Note on materials	RoHS-compliant
Material housing	Aluminium Anodised