


Series sub-base VIGK-04-D-1

Part number: 30424

FESTO

For valve terminal

Products to be discontinued. Available until 2011.

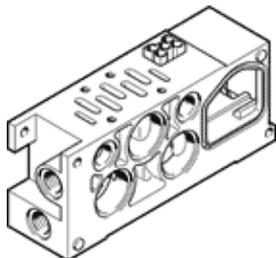

Data sheet

Feature	Value
Based on the standard	ISO 5599-2
Max. number of valve positions	1
Operating pressure	-0.9 ... 16 bar
Operating medium	Filtered compressed air
Medium temperature	-10 ... 60 °C
Ambient temperature	-10 ... 60 °C
Authorisation	UL - Recognized (OL)
Mounting method for sub-base	with through hole
Pneumatic connection, port 1	G1/2
Pneumatic connection, port 2	G1/4
Pneumatic connection, port 3	G1/2
Pneumatic connection, port 4	G1/4
Pneumatic connection, port 5	G1/2
Materials information for sub-base	Aluminium die cast