


Intermediate pressure regulator plate LR-ZP-P-D-3

Part number: 35968

FESTO

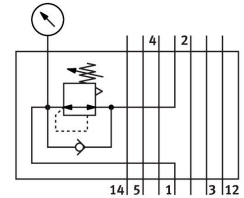

Data sheet

| Feature | Value |
|---------------------------|--|
| Based on standard | ISO 5599-1 |
| Integrated function | Pressure regulator |
| Design | Piston |
| Pressure regulation range | 0 MPa...1.2 MPa 0 bar...12 bar 0 psi...174 psi |
| Inlet pressure 1 | 14 bar 1.4 MPa 203 psi |
| Approval | UL - Recognized (OL) |
| LABS (PWIS) conformity | VDMA24364 zone III |
| Product weight | 1220 g |
| Note on materials | RoHS-compliant |
| Material seals | NBR |
| Material housing | Die-cast aluminium Steel |