


## Barbed hose fitting N-3/8-P-13

Part number: 36160

**FESTO**

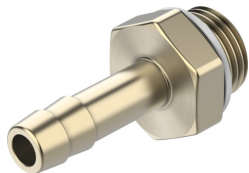

### Data sheet

Feature	Value
Nominal size	11 mm
Type of seal on screwed plug	Sealing ring
Mounting position	optional
Design	Straight design
Size of pack	1
Operating pressure complete temperature range	-0.95 bar...16 bar
Operating medium	Compressed air to ISO 8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible (in which case lubricated operation will always be required)
Corrosion resistance class CRC	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Ambient temperature	-10 °C...60 °C
Max. tightening torque	15 Nm
Product weight	178 g
Pneumatic connection, port 1	Male thread G3/8
Pneumatic connection, port 2	For tubing inside diameter of 13 mm
Note on materials	RoHS-compliant
Material housing	Anodised aluminium