


# quick coupling plug KS5-N-13

Part number: 4089  
Product to be discontinued

FESTO

For self-closing quick coupling connectors.

Type to be discontinued. Available until 2019. See Support Portal for alternative products.

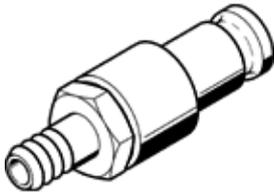

## Data sheet

Feature	Value
Nominal size	11 mm
Operating pressure complete temperature range	0 ... 12 bar
Standard nominal flow rate	1,710 l/min
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible
Corrosion resistance classification CRC	1 - Low corrosion stress
Ambient temperature	-10 ... 60 °C
Product weight	256 g
Pneumatic connection, port 1	N-13