


Manifold block MHP2-PR8-5

Part number: 525125

FESTO

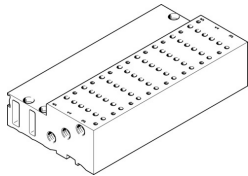

Data sheet

| Feature | Value |
|--------------------------------|----------------------------------|
| Max. number of valve positions | 8 |
| Corrosion resistance class CRC | 2 - Moderate corrosion stress |
| LABS (PWIS) conformity | VDMA24364-B1/B2-L |
| Product weight | 511 g |
| Mounting method for sub-base | With through-hole With H-rail |
| Mounting method for valve | Via female thread |
| Pneumatic connection, port 1 | M7 |
| Pneumatic connection, port 3 | M7 |
| Pneumatic connection, port 5 | M7 |
| Material sub-base | Wrought aluminium alloy |