


Manifold block MHP2-PR10-5

Part number: 525126

FESTO

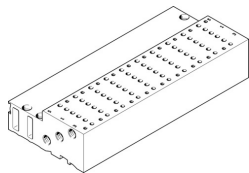

Data sheet

Feature	Value
Max. number of valve positions	10
Corrosion resistance class CRC	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Product weight	597 g
Mounting method for sub-base	With through-hole With H-rail
Mounting method for valve	Via female thread
Pneumatic connection, port 1	M7
Pneumatic connection, port 3	M7
Pneumatic connection, port 5	M7
Material sub-base	Wrought aluminium alloy