


# Manifold block VIGK-04-D-2-1/2

Part number: 525570

FESTO

For valve terminal 04, high flow rate, size 2 ISO valves (G 1/2)

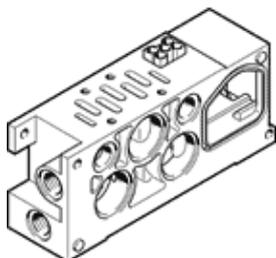

## Data sheet

Feature	Value
Based on the standard	ISO 5599-2
Max. number of valve positions	1
Operating pressure	-0.9 ... 16 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7::-]
Medium temperature	-10 ... 60 °C
Protection class	IP65
Ambient temperature	-10 ... 60 °C
Mounting method for sub-base	with through hole
Pneumatic connection, port 1	G3/4
Pneumatic connection, port 2	G1/2
Pneumatic connection, port 3	G3/4
Pneumatic connection, port 4	G1/2
Pneumatic connection, port 5	G3/4
Materials information for sub-base	Aluminium die cast