


Filter silencer LFU-1/4

Part number: 539132

FESTO

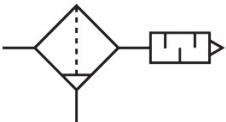

Data sheet

Feature	Value
Size	G1/4
Mounting position	Vertical +/-5°
Grade of filtration	1 µm
Condensate drain	Manually rotating
Operating pressure	0 MPa...1.6 MPa 0 bar...16 bar 0 psi...232 psi
Flow rate to atmosphere	4000 l/min
Operating medium	Compressed air to ISO 8573-1:2010 [7:4:4]
Note on operating and pilot medium	Lubricated operation possible (in which case lubricated operation will always be required)
Noise reduction	Reduction by 40 dB
Corrosion resistance class CRC	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Sound pressure level	78 dB(A)
Ambient temperature	-10 °C...60 °C
Product weight	190 g
Pneumatic connection	G1/4
Material housing	PP