 



# Throttle plate

## VABF-S4-2-F1B1-C

Part number: 540176

FESTO

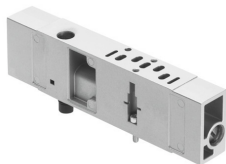

### Data sheet

| Feature                                      | Value  |
|--|--|
| Construction width                           | 18 mm  |
| Based on standard                            | ISO 15407-2  |
| Mounting position                            | optional   |
| Operating pressure                           | 1 MPa<br>10 bar  |
| CE mark (see declaration of conformity)      | To EU Low Voltage Directive  |
| UKCA marking (see declaration of conformity) | To UK regulations for electrical equipment   |
| Operating medium                             | Compressed air to ISO 8573-1:2010 [7:4:4]  |
| Note on operating and pilot medium           | Lubricated operation possible (in which case lubricated operation will always be required) |
| Corrosion resistance class CRC               | 0 - No corrosion stress  |
| LABS (PWIS) conformity                       | VDMA24364-B1/B2-L  |
| Degree of protection                         | IP65<br>NEMA 4   |
| Pilot medium                                 | Compressed air to ISO 8573-1:2010 [7:4:4]  |
| Ambient temperature                          | -5 °C...50 °C  |
| Product weight                               | 228 g  |
| Mounting with vertical stacking              | On manifold sub-base<br>On individual sub-base   |
| Material housing                             | Die-cast aluminium   |