


**Distributor**  
**FR-8-1/4-BR**  
Part number: 546750

**FESTO**

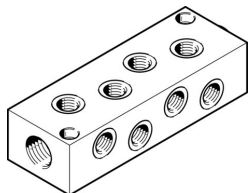

**Data sheet**

Feature	Value
Nominal size	11.5 mm
Mounting position	optional
Operating pressure complete temperature range	0 bar...16 bar
Operating medium	Compressed air to ISO 8573-1:2010 [7:...]
Note on operating and pilot medium	Lubricated operation possible (in which case lubricated operation will always be required)
Corrosion resistance class CRC	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Number of outputs	8
Number of supply lines	1
Pneumatic connection, port 1	G1/2
Pneumatic connection, port 2	G1/4
Material housing	Wrought aluminium alloy