


**Vacuum filter**  
**VAF-DB-1/4**  
Part number: 547 261

**FESTO**

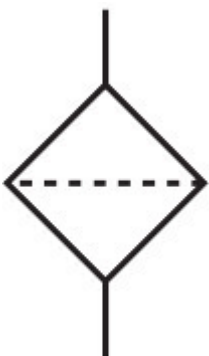

**Data sheet**

Feature	Value
Mounting position	Vertical
Grade of filtration	80 µm
Operating pressure	-0.95 bar...0 bar
Note on operating pressure	Only for use in open vacuum systems
Operating medium	Compressed air to ISO 8573-1:2010 [7:-:-]
LABS (PWIS) conformity	VDMA24364 zone III
Ambient temperature	-5 °C...50 °C
Max. tightening torque	8.7 Nm
Product weight	71 g
Type of mounting	In-line installation Via wall/ surface bracket
Pneumatic connection	G1/4
Vacuum connection	G1/4
Note on materials	RoHS-compliant
Material seals	NBR
Material filter	PE
Material housing	PP reinforced
Material bowl	PA
Suitable for ejector pulse	7 bar