 



# Roller lever valve

## RWB-3-1/8

Part number: 552432

FESTO

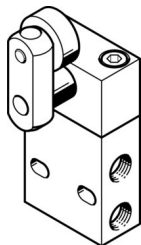

### Data sheet

Feature	Value
Valve function	3/2-way, closed, monostable
Type of actuation	Mechanical
Standard nominal flow rate (standardised to DIN 1343)	120 l/min
pneumatic working port	G1/8
Operating pressure	3.5 bar...8 bar
Design	Piston seat
Nominal size	3.5 mm
Type of piloting	Pilot actuated
Corrosion resistance class CRC	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Ambient temperature	-10 °C...60 °C
Actuating force	3.1 N
Product weight	160 g
Type of mounting	With through-hole
Pneumatic connection, port 1	G1/8
Pneumatic connection, port 2	G1/8
Pneumatic connection, port 3	G1/8
Material seals	NBR
Material housing	Wrought aluminium alloy Anodised