


Vacuum filter

VAF-DB-3/8

Part number: 553140

FESTO

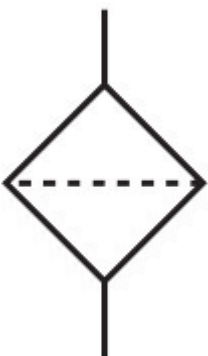

Data sheet

Feature	Value
Mounting position	Vertical
Grade of filtration	80 µm
Operating pressure	-0.95 bar...0 bar
Note on operating pressure	Only for use in open vacuum systems
Operating medium	Compressed air to ISO 8573-1:2010 [7:-:-]
LABS (PWIS) conformity	VDMA24364 zone III
Ambient temperature	-5 °C...50 °C
Max. tightening torque	15.3 Nm
Product weight	156 g
Type of mounting	In-line installation Via wall/ surface bracket
Pneumatic connection	G3/8
Vacuum connection	G3/8
Note on materials	RoHS-compliant
Material seals	NBR
Material filter	PE
Material housing	PP reinforced
Material bowl	PA
Suitable for ejector pulse	7 bar