


Vacuum filter
VAF-DB-1/2
Part number: 553141

FESTO

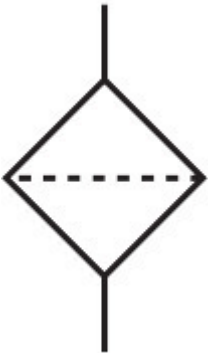

Data sheet

Feature	Value
Mounting position	Vertical
Grade of filtration	80 µm
Operating pressure	-0.95 bar...0 bar
Note on operating pressure	Only for use in open vacuum systems
Operating medium	Compressed air to ISO 8573-1:2010 [7:-:-]
LABS (PWIS) conformity	VDMA24364 zone III
Ambient temperature	-5 °C...50 °C
Max. tightening torque	20.5 Nm
Product weight	162 g
Type of mounting	In-line installation Via wall/ surface bracket
Pneumatic connection	G1/2
Vacuum connection	G1/2
Note on materials	RoHS-compliant
Material seals	NBR
Material filter	PE
Material housing	PP reinforced
Material bowl	PA
Suitable for ejector pulse	7 bar