
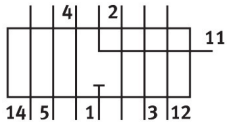


Vertical pressure supply plate

VABF-S1-2-P1A3-G12

Part number: 555785

FESTO

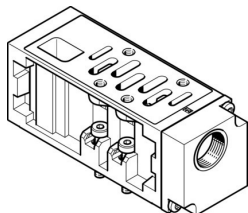

Data sheet

Feature	Value
Construction width	54 mm
Based on standard	ISO 5599-1
Mounting position	optional
Vertical pneumatic linkage	Alternative compressed air supply for 1
Operating pressure	-0.09 MPa...1 MPa -0.9 bar...10 bar
Inlet pressure 1	0.5 bar...10 bar 0.05 MPa...1 MPa 7.25 psi...145 psi
Standard nominal flow rate (standardised to DIN 1343)	2800 l/min
Operating medium	Compressed air to ISO 8573-1:2010 [7:4:4]
Note on operating and pilot medium	Lubricated operation possible (in which case lubricated operation will always be required)
Corrosion resistance class CRC	0 - No corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Degree of protection	IP65 NEMA 4
Ambient temperature	-5 °C...50 °C
Product weight	605 g
Mounting with vertical stacking	On manifold sub-base On individual sub-base
Pneumatic connection, port 1	G1/2
Note on materials	RoHS-compliant
Material housing	Die-cast aluminium