


**Axial kit**  
**EAMM-A-P5-28B-42A**  
Part number: 562640

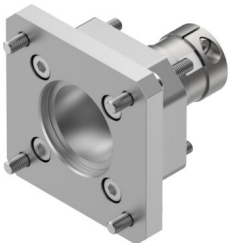

**Data sheet**

| Feature                        | Value                  |
|--------------------------------|------------------------|
| Nominal length                 | 16.5 mm                |
| Mounting position              | optional               |
| Max. rotational speed          | 10000 rpm              |
| LABS (PWIS) conformity         | VDMA24364-B2-L         |
| Storage temperature            | -25 °C...60 °C         |
| Relative air humidity          | 0 - 95%                |
| Degree of protection           | IP40                   |
| Ambient temperature            | -10 °C...60 °C         |
| Mass moment of inertia         | 0.28 kgmm <sup>2</sup> |
| Transmittable torque           | 1.1 Nm                 |
| Product weight                 | 60 g                   |
| Interface code, actuator       | P5-28B                 |
| Interface code, motor in       | 42A                    |
| Interface code, clutch housing | 28B                    |
| Note on materials              | RoHS-compliant         |