


AS-i module CESA-GW-AS-PB

Part number: 567032
Product to be discontinued

FESTO

Type to be discontinued. Available until 2021. See Support Portal for alternative products.

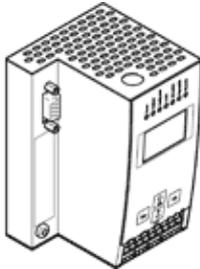

Data sheet

Feature	Value
Dimensions W x L x H	75 mm x 120 mm x 83 mm
Control elements	4 keys
Status displays	LCD display Yellow LED planning mode Green LED AS-i normal operation Green LED AS-i voltage OK Green LED PROFIBUS master Green LED slave programming Green LED voltage ON Red LED configuration error
Operating voltage	AS-i voltage 30 V DC
Current consumption	200 mA from the AS-interface circuit
Authorisation	C-Tick c UL us - Listed (OL)
CE mark (see declaration of conformity)	to EU directive for EMC
Corrosion resistance classification CRC	0 - No corrosion stress
Storage temperature	-25 ... 85 °C
Protection class	IP20
Ambient temperature	0 ... 55 °C
Test for insensitivity to shock	to EN 61131-2
Test for insensitivity to vibration	to EN 61131-2
Product weight	460 g
Fieldbus interface, transmission rate	9.6 kbit/s up to 12 mbit/s
Fieldbus interface, connection technology	Socket Sub-D 9-pin
Fieldbus interface	PROFIBUS to DIN 19245 Part 3
Programming/diagnostic interface	Serial interface RS 232
Materials note	Contains PWIS substances Conforms to RoHS
Material housing	High alloy steel, non-corrosive