


Sub-base VMPAC-AP-14-B-2

Part number: 576575

FESTO

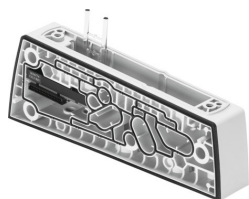

Data sheet

Feature	Value
Width	32.8 mm
Length	169 mm
Grid dimension	26.8 mm
Max. number of valve positions	1
Operating pressure	-0.9 bar...8 bar
Pilot pressure	3 bar...8 bar
Corrosion resistance class CRC	4 - Very high corrosion stress
LABS (PWIS) conformity	VDMA24364-B2-L
Ambient temperature	-5 °C...50 °C
Product weight	160 g
Pneumatic connection, port 2	G1/4
Pneumatic connection, port 4	G1/4
Note on materials	RoHS-compliant
Material housing	PA-reinforced