


# OR gate OS-PK-3

Part number: 6684

FESTO

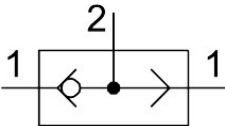

## Data sheet

Feature	Value
Valve function	OR function
Pneumatic connection, port 1	PK-3
Pneumatic connection, port 2	PK-3
Type of mounting	With through-hole
Standard nominal flow rate (standardised to DIN 1343)	120 l/min
Operating pressure	1.6 bar...8 bar
Ambient temperature	-10 °C...60 °C
Material housing	POM
Operating medium	Compressed air to ISO 8573-1:2010 [7:-:-]
Nominal size	2.4 mm
Mounting position	optional
Note on operating and pilot medium	Lubricated operation possible (in which case lubricated operation will always be required)
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Media temperature	-10 °C...60 °C
Product weight	9 g
Pneumatic connection, port 3	PK-3
Note on materials	RoHS-compliant
Material seals	NBR