


Pressure gauge MA-63-0,25

Part number: 7169

FESTO

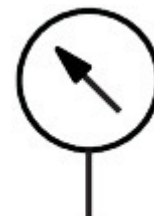

Data sheet

Feature	Value
Indicating range	0 bar...0.25 bar 0 psi...3.6 psi
Conforms to standard	DIN EN 837-3
Nominal size of pressure gauge	63
Explosion protection	The information in the certificate must be observed! Zone 1 (ATEX) Zone 2 (ATEX) Zone 21 (ATEX) Zone 22 (ATEX)
Type of mounting	In-line installation
Operating medium	Liquid media Gaseous media
Note on operating and pilot medium	No acetylene No oxygen
Operating pressure	0 bar...0.25 bar
Alternating load factor	0.9
Continuous load factor	0.75
Measurement accuracy class	1.6
Degree of protection	IP43
Media temperature	-20 °C...80 °C
Ambient temperature	-20 °C...60 °C
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Position of connection	Centred, rear side
Pneumatic connection	G1/4
Material screwed plug	Brass
Material housing	Steel
Material screen	PMMA
Product weight	180 g