


Micro stem actuated valve S-3-PK-3-B

Part number: 7843

FESTO

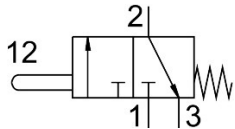

Data sheet

Feature	Value
Valve function	3/2-way, closed, monostable
Type of actuation	Mechanical
Standard nominal flow rate (standardised to DIN 1343)	60 l/min
pneumatic working port	PK-3
Operating pressure	-0.95 bar...8 bar
Design	Poppet valve with spring return
Type of reset	Mechanical spring
Nominal size	1.8 mm
Sealing principle	Soft
Mounting position	optional
Type of piloting	Direct
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Ambient temperature	-10 °C...60 °C
Actuating force	6 N
Product weight	7 g
Type of mounting	With through-hole
Pneumatic connection, port 1	PK-3
Pneumatic connection, port 2	PK-3
Material housing	Polymer Brass