


**Flow control**  
**VFFG-T-M5-5**  
Part number: 8025709

**FESTO**

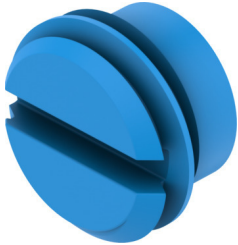

**Data sheet**

| Feature                                              | Value                                                                                      |
|------------------------------------------------------|--------------------------------------------------------------------------------------------|
| Valve function                                       | Flow control function                                                                      |
| Type of mounting                                     | Via thread                                                                                 |
| Standard nominal flow rate in flow control direction | 9.6 l/min                                                                                  |
| Operating pressure                                   | -0.9 bar...10 bar                                                                          |
| Ambient temperature                                  | -5 °C...60 °C                                                                              |
| Nominal size                                         | 0.5 mm                                                                                     |
| b value                                              | 0.5                                                                                        |
| C value                                              | 0.04 l/sbar                                                                                |
| Operating medium                                     | Compressed air to ISO 8573-1:2010 [7:4:4]                                                  |
| Note on operating and pilot medium                   | Lubricated operation possible (in which case lubricated operation will always be required) |
| LABS (PWIS) conformity                               | VDMA24364-B1/B2-L                                                                          |
| Storage temperature                                  | -20 °C...60 °C                                                                             |
| Product weight                                       | 0.5 g                                                                                      |
| Note on materials                                    | RoHS-compliant                                                                             |
| Material hollow bolt                                 | PA                                                                                         |