


Supply plate VABF-B10-25-P1-G14

Part number: 8026317

FESTO

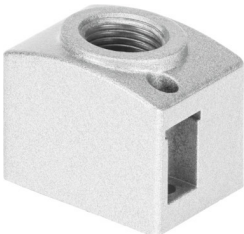

Data sheet

Feature	Value
Operating pressure	-0.09 MPa...1 MPa -0.9 bar...10 bar
Corrosion resistance class CRC	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Max. tightening torque	3 Nm
Product weight	26 g
Type of mounting	With through-hole
Pneumatic connection, port 1	G1/4
Note on materials	RoHS-compliant
Material supply plate	Die-cast aluminium