


Sub-base VMPA-FB-AP-1-P5

Part number: 8093454

FESTO

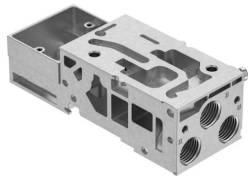

Data sheet

Feature	Value
Width	42 mm
Length	107.3 mm
Grid dimension	41 mm
Max. number of valve positions	4
Operating pressure	-0.09 MPa...1 MPa -0.9 bar...10 bar
Pilot pressure	0.3 MPa...0.8 MPa 3 bar...8 bar
Corrosion resistance class CRC	0 - No corrosion stress
LABS (PWIS) conformity	VDMA24364 zone III
Storage temperature	-20 °C...60 °C
Ambient temperature	-5 °C...50 °C
Product weight	155 g
Pneumatic connection, port 1	G1/4
Note on materials	RoHS-compliant
Material sub-base	Die-cast aluminium