


Axial kit
EAMM-A-D19-38AA
Part number: 8105863

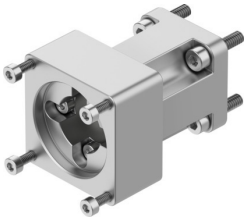

Data sheet

Feature	Value
Mounting position	optional
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C...60 °C
Relative air humidity	0 - 95%
Degree of protection	IP40
Ambient temperature	-10 °C...60 °C
Transmittable torque	1.1 Nm
Product weight	121 g
Interface code, actuator	D19
Interface code, motor in	38AA
Note on materials	RoHS-compliant