


Manifold block-SET VABS-C12-6-S

Part number: 8122790

FESTO

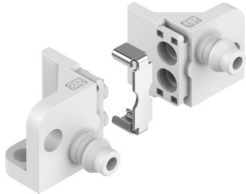

Data sheet

Feature	Value
Construction width	13 mm
Mounting position	optional
Design	Connection direction at side
Max. number of valve positions	Versions according to customer specifications possible
Operating pressure	-0.1 MPa...0.7 MPa -1 bar...7 bar
Operating medium	Compressed air to ISO 8573-1:2010 [6:4:1]
Note on operating and pilot medium	Maximum particle size 5 µm
LABS (PWIS) conformity	VDMA24364 zone III
Ambient temperature	5 °C...50 °C
Product weight	3 g
Type of mounting	With through-hole
Pneumatic connection, port 2	For tubing I.D. 4 mm
Note on materials	RoHS-compliant
Material manifold rail	PBT