


**Axial kit**  
**EAMM-A-D50-80PB**  
Part number: 8123493

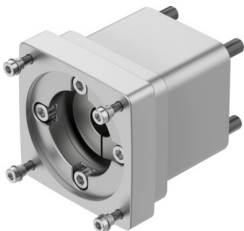

**Data sheet**

| Feature                  | Value          |
|--------------------------|----------------|
| Mounting position        | optional       |
| LABS (PWIS) conformity   | VDMA24364-B2-L |
| Storage temperature      | -25 °C...60 °C |
| Relative air humidity    | 0 - 95%        |
| Degree of protection     | IP40           |
| Ambient temperature      | -10 °C...60 °C |
| Transmittable torque     | 17 Nm          |
| Product weight           | 892 g          |
| Interface code, actuator | D50            |
| Interface code, motor in | 80PB<br>80R    |
| Note on materials        | RoHS-compliant |